


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

XB6ECV4BP

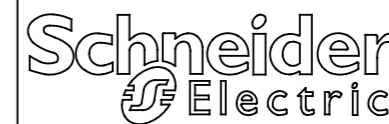

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Degree of Protection: IP 65
 Storage Temperature Range: -40 to +70 °C
 Operating Temperature Range: -10 to +55 °C
 Contact Type:
 AC Supply Utilization Category:
 Certifications: IEC 60947-1, IEC 60947-5-1, JIS C 4520, JIS C 852, UL 508, CSA C22.2 No 14

Description: Pilot Light, Square, red, 24V,
Vibration Resistance: 1 mm (10...55 Hz)
Mechanical Shock Resistance: 10 gn (duration = 11 ms) for half sine wave acceleration
Mechanical Life (in operating cycles): NA

Specification: