


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

XB6ECW6B2P

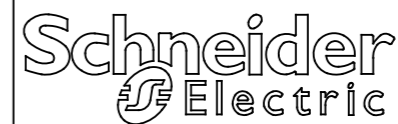

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Degree of Protection: IP 65
 Storage Temperature Range: -40 to +70 °C
 Operating Temperature Range: -10 to +55 °C
 Contact Type: 2 C/O
 AC Supply Utilization Category: AC12, 120V-1.5A; 240V-1A; AC13, 120V-1A; 240V-0.7A
 Certifications: IEC 60947-1, IEC 60947-5-1, JIS C 4520, JIS C 852, UL 508, CSA C22.2 No 14

Specification:

Description: Illuminated Push Button Spring Return, Square, blue, 24V, 2 NO/NC
 Vibration Resistance: 1 mm (10...55 Hz)
 Mechanical Shock Resistance: 10 gn (duration = 11 ms) for half sine wave acceleration
 Mechanical Life (in operating cycles): 1000000