


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**XVBC8G5**

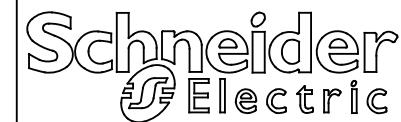

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

UL File: E164353 CCN NKCR  
 CSA File: LR44087 Class 3211-03  
 CE Marked: Yes  
 RoHS compliant: Yes  
 NEMA / IP Rating: NEMA 4X/12 - IP65

**Specification:**

Description:  
 Size: 70mm diameter  
 Housing Color: Black  
 Lens Color: Orange  
 Bulb Color: not applicable  
 Supply Voltage: 120V AC  
 Signaling Effect: Strobging Light (10 Joules)  
 Mounting Type: Integrated Locking Ring  
 Terminal Type: Screw Clamp  
 Cable Length:  
 Comments: includes integral strobe - do not order separate bulb