


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:  
**XVBL4B4**

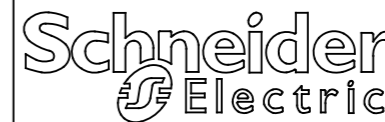

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

UL File: E164353 CCN NKCR  
 CSA File: LR44087 Class 3211-03  
 CE Marked: Yes  
 RoHS compliant: Yes  
 NEMA / IP Rating: NEMA 4X/12 - IP65

**Specification:**

Description:  
 Size: 70mm diameter  
 Housing Color: Black  
 Lens Color: Red  
 Bulb Color: not applicable  
 Supply Voltage: 24V AC - 24/48V DC  
 Signaling Effect: Flashing Light (10W max bulb)  
 Mounting Type: Direct or Tube  
 Terminal Type: Screw Clamp  
 Cable Length:  
 Comments: must order bulb separately