


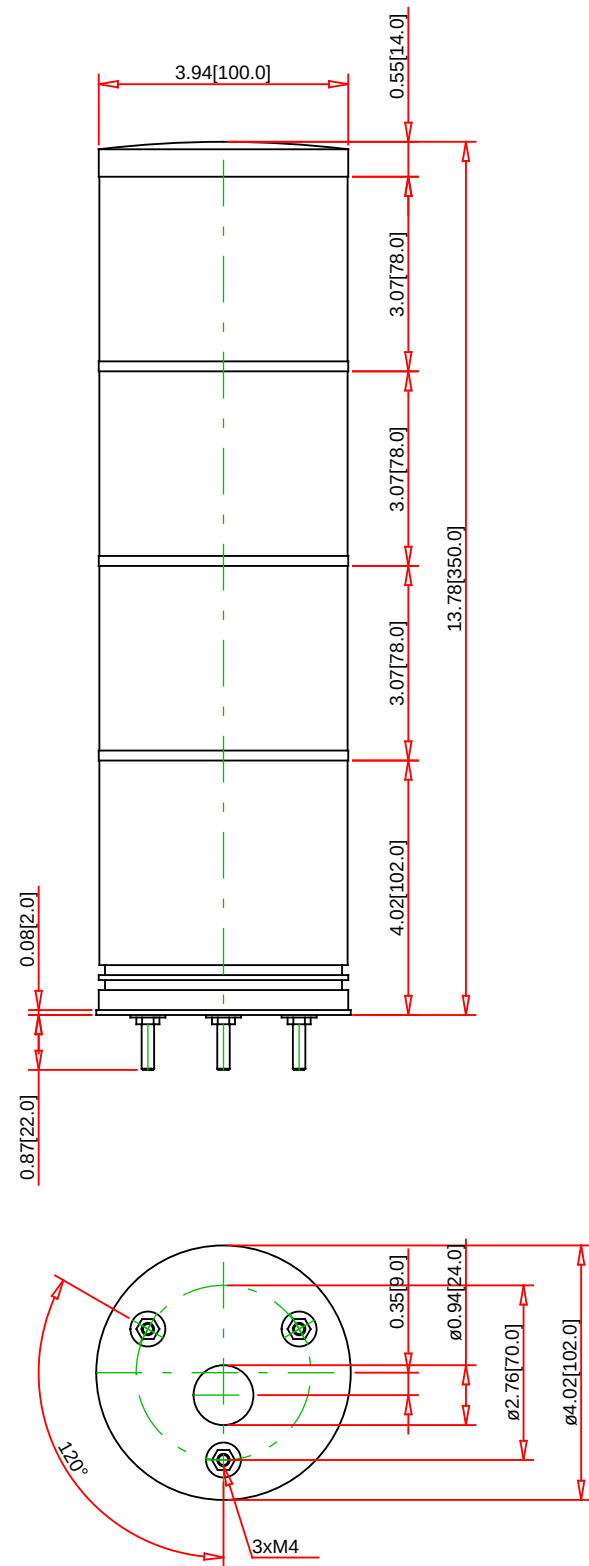

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

XVC1B3K



Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

Specification:

UL File: E164353 CCN NKCR
CSA File: LR44087 Class 3211-03
CE Marked: Yes
RoHS compliant: Yes
NEMA / IP Rating: NEMA 3R/12 - IP 54

Description:
Size: 100mm diameter
Housing Color: Red, Orange and Green
Lens Color: Red, Orange and Green
Bulb Color: Red, Orange and Green
Supply Voltage: 24V AC/DC
Signaling Effect: Steady or Flashing Light (Integral LED) w/o buzzer
Mounting Type: Base
Terminal Type: 500mm
Cable Length: Pre-Wired and Pre-Assembled
Comments: