


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**ZB4BC38003RA**

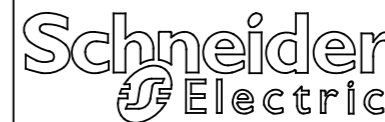

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

UL Cert.:	E164353 CCN NKCR
CSA Cert.:	LR44087 Class 3211 03
CE Cert.:	CE per IEC
IP Protection:	P 66 IP 69K
NEMA Protection:	NEMA 4, 12, 13
IK Protection:	IK03
Ambient Air Temp. (for storage):	-40 to +85 °C
Ambient Air Temp. (for operation):	-40 to +70°C
Electric Shock Protection:	Class I
Washdown Resistance (in Pa):	90 Pa

**Specification:**

Description:	22MM HARSH PB, GREEN, W/ MARKING, ROTATE 90°
Mechanical Durability (in operating cycles):	3000000
Vibration Resistance:	5 gn
Mechanical Shock Resistance:	30 gn
Color:	Green
Button Marking:	w/, rotate 90°