


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ZB4BW031

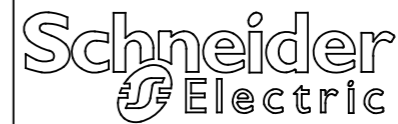

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Tightening Torque: 0.8 Nm
 Light Module Electrical Consumption: 24V = 18mA; 120/240V = 14mA
 CE: Yes
 RoHS: Yes
 Contact Configuration: 1 N.O.
 Light Module Supply Voltage: n/a

Specification:

Description: Base, Contact, & Light Module
 Light Module Type: Transformer, BA9 bulb
 Light Module Voltage: 110-120Vac
 Ampere Rating: 10A
 Contact Material: Silver Alloy
 Terminal Type: Screw Clamp
 Utilization Category: AC-15; DC-13
 Used On: ZB4 Metal Operators