
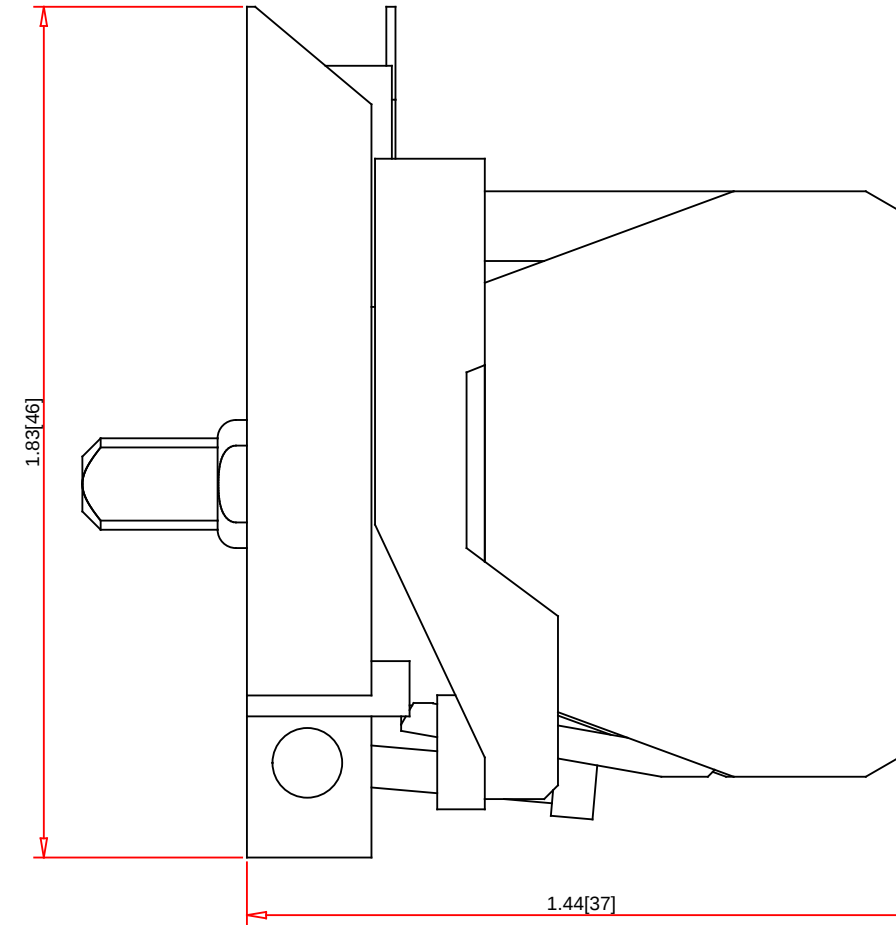


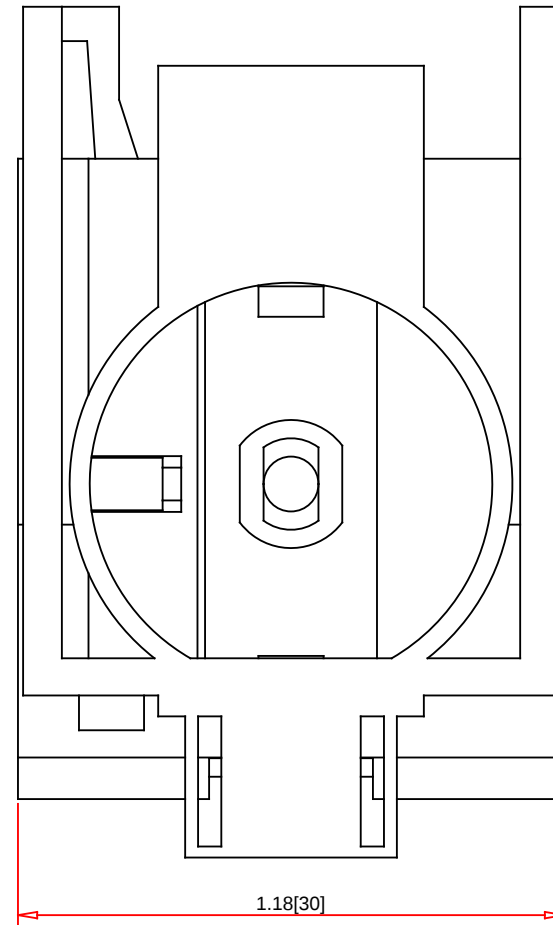

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
ZB4BW0G11

Schneider Electric
Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 877 342 5173
Email: CCC@us.schneider-electric.com

Technical Information:
Tightening Torque: 0.8 Nm
Light Module Electrical Consumption: 24V = 18mA; 120/240V = 14mA
CE: Yes
RoHS: Yes
Contact Configuration: 1 N.O.
Light Module Supply Voltage: n/a

Specification:
Description: Base, Contact, & Light Module
Light Module Type: LED (White)
Light Module Voltage: 110-120Vac
Ampere Rating: 10A
Contact Material: Silver Alloy
Terminal Type: plug in
Utilization Category: AC-15; DC-13
Used On: ZB4 Metal Operators