

# Asfora

Svakodnevni stil



## Asfora

# Asfora čini vaš život jednostavnijim...



Prekidač, 1P, beli



Prekidač, 1P, krem



## Osvetljenje i komfort



### Prekidač za roletne

Podesite prirodno svetlo u zavisnosti od vremena i raspoloženja.



### Prekidač sa lokatorom

Jednostavno pronađite prekidač za svetlo u mraku.



### Dimer

Napravite pravi ambijent.



## Povezanost



### Utičnice TV/R/SAT

Pristup svim media uređajima sa jednog mesta.



### Računarska utičnica RJ45

Za digitalni svet na dohvat ruke.



### Utičnica za zvučnike

Uživajte u muzici sa jednog mesta u kući i sakrijte kablove u zidovima.

## Sigurnost na prvom mestu



**Dizajn priključaka**, minimizuje kontakt sa električnim delovima. Tunnel terminali prekrivaju celokupnu dužinu ogoljene žice, sprečavajući kratak spoj.



**Dijagram ožičavanja**, sa zadnje strane mehanizma, omogućava izbegavanje grešaka.

## Brza i jednostavna instalacija



**Žabicama** se jednostavno rukuje zahvaljujući čemu je prekidače jednostavno uključiti i isključiti.



**Ulazni priključci** su u obliku tunela.



**Priključci su postavljeni u jednoj liniji**, pa se sve žice zajedno mogu iseći na istu dužinu.




**Jednostavno pričvršćivanje montažnog rama** omogućava fino podešavanje svake jedinice za perfektu završnicu.

## Pouzdanost i robusnost



**Galvanizovani metalni montažni ramovi** su čvrsti i otporni na koroziju.

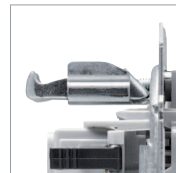

**Šrafovi za montažu** su dugački i čvrsti.



Asfora serija ima adekvatan dizajn i vrhunski kvalitet proizvoda, kakav očekujete od Schneider Electric-a.



## Prekidači 10AX - 250V



1P	
Boja	
<input type="checkbox"/> bela	EPH0100321
<input type="checkbox"/> bež	EPH0100323



Serijski prekidač	
Boja	
<input type="checkbox"/> bela	EPH0300321
<input type="checkbox"/> bež	EPH0300323



Naizmienični prekidač	
Boja	
<input type="checkbox"/> bela	EPH0400321
<input type="checkbox"/> bež	EPH0400323



Dvostruki naizmienični prekidač	
Boja	
<input type="checkbox"/> bela	EPH0600121
<input type="checkbox"/> bež	EPH0600123



Unakrsni prekidač	
Boja	
<input type="checkbox"/> bela	EPH0500321
<input type="checkbox"/> bež	EPH0500323



Kartični prekidač	
Boja	
<input type="checkbox"/> bela	EPH6200121
<input type="checkbox"/> bež	EPH6200123



Prekidač za roletne	
Boja	
<input type="checkbox"/> bela	EPH1300321
<input type="checkbox"/> bež	EPH1300323

## Tasteri 10AX - 250V



Taster	
Boja	
<input type="checkbox"/> bela	EPH0800321
<input type="checkbox"/> bež	EPH0800323



Taster sa simbolom „zvono“	
Boja	
<input type="checkbox"/> bela	EPH0800121
<input type="checkbox"/> bež	EPH0800123



Taster sa simbolom „svetlo“	
Boja	
<input type="checkbox"/> bela	EPH0900121
<input type="checkbox"/> bež	EPH0900123

## Prekidač sa lokatorom 10AX - 250V



1P sa lampicom	
Boja	
<input type="checkbox"/> bela	EPH1400321
<input type="checkbox"/> bež	EPH1400323



Naizmienični prekidač sa lampicom	
Boja	
<input type="checkbox"/> bela	EPH1500321
<input type="checkbox"/> bež	EPH1500323

## Prekidač sa lokatorom 16AX - 250V



1P	
Boja	
<input type="checkbox"/> bela	EPH1430321
<input type="checkbox"/> bež	EPH1430323

## Tasteri sa lampicom i simbolima 10AX - 250V



Taster sa lampicom	
Boja	
<input type="checkbox"/> bela	EPH1600321
<input type="checkbox"/> bež	EPH1600323



Taster sa lampicom i simbolom „zvono“	
Boja	
<input type="checkbox"/> bela	EPH1700321
<input type="checkbox"/> bež	EPH1700323



Taster sa lampicom i simbolom „svetlo“	
Boja	
<input type="checkbox"/> bela	EPH1800121
<input type="checkbox"/> bež	EPH1800123



Taster sa lampicom i simbolom „stepenice“	
Boja	
<input type="checkbox"/> bela	EPH1900321
<input type="checkbox"/> bež	EPH1900323

## Dimer



Dimer, RL 40-600VA	
Boja	
<input type="checkbox"/> bela	EPH6400121
<input type="checkbox"/> bež	EPH6400123



Dimer, RC 20-315VA	
Boja	
<input type="checkbox"/> bela	EPH6600121
<input type="checkbox"/> bež	EPH6600123

## Dimeri sa lokatorom



Dimer sa lokatorom, RL 40-600VA	
Boja	
<input type="checkbox"/> bela	EPH6500121
<input type="checkbox"/> bež	EPH6500123

EPH64001..	EPH65001..	EPH66001..		
Osigurač F6.3AH		Elektronska	Zaštita od kratkog spoja	
			Tip opterećenja	
40-600 W	40-600 W	20-315 W		sijalica sa užarenim vlaknom 230 V AC
40-600 W	40-600 W	20-315 W		halogene sijalice 230 V AC
40-600 VA	40-600 VA	-		LV halogene sijalice sa feromagnetskim transformatorom 12 V
-	-	20-315 VA		LV halogene sijalice sa elektronskim transformatorom

## Utičnice 16AX - 250V



2P+PE	
Boja	
<input type="checkbox"/> bela	EPH2900121
<input type="checkbox"/> bež	EPH2900123



2P+PE sa zaštitom	
Boja	
<input type="checkbox"/> bela	EPH2900221
<input type="checkbox"/> bež	EPH2900223



2P+PE crvena	
Boja	
<input type="checkbox"/> bela	EPH2900521
<input type="checkbox"/> bež	EPH2900523



2P+PE sa poklopcem	
Boja	
<input type="checkbox"/> bela	EPH3100121
<input type="checkbox"/> bež	EPH3100123



2P+PE sa poklopcem i zaštitom, IP44	
Boja	
<input type="checkbox"/> bela	EPH3100321
<input type="checkbox"/> bež	EPH3100323



Dvostruka 2P+PE	
Boja	
<input type="checkbox"/> bela	EPH9900121
<input type="checkbox"/> bež	EPH9900123

## Telefonske utičnice



1xRJ11	
Boja	
<input type="checkbox"/> bela	EPH4100121
<input type="checkbox"/> bež	EPH4100123



2xRJ11	
Boja	
<input type="checkbox"/> bela	EPH4200121
<input type="checkbox"/> bež	EPH4200123

## Komunikacione utičnice



1xRJ45, kat. 5e UTP	
Boja	
<input type="checkbox"/> bela	EPH4300121
<input type="checkbox"/> bež	EPH4300123



2xRJ45, kat. 5e UTP	
Boja	
<input type="checkbox"/> bela	EPH4400121
<input type="checkbox"/> bež	EPH4400123



1xRJ45, kat. 6 UTP	
Boja	
<input type="checkbox"/> bela	EPH4700121
<input type="checkbox"/> bež	EPH4700123



2xRJ45, kat. 6 UTP	
Boja	
<input type="checkbox"/> bela	EPH4800121
<input type="checkbox"/> bež	EPH4800123

## Utičnica za zvučnike



Utičnica za zvučnike	
Boja	
<input type="checkbox"/> bela	EPH5700121
<input type="checkbox"/> bež	EPH5700123

## TV, TV/R, TV/SAT utičnice



TV završna (1dB)	
Boja	
<input type="checkbox"/> bela	EPH3200121
<input type="checkbox"/> bež	EPH3200123



TV/R završna (1dB)	
Boja	
<input type="checkbox"/> bela	EPH3300121
<input type="checkbox"/> bež	EPH3300123



TV/R prolazna (4dB)	
Boja	
<input type="checkbox"/> bela	EPH3300221
<input type="checkbox"/> bež	EPH3300223



TV/R prolazna (8dB)	
Boja	
<input type="checkbox"/> bela	EPH3300321
<input type="checkbox"/> bež	EPH3300323



TV/SAT završna (1dB)	
Boja	
<input type="checkbox"/> bela	EPH3400121
<input type="checkbox"/> bež	EPH3400123



TV/SAT prolazna (4dB)	
Boja	
<input type="checkbox"/> bela	EPH3400221
<input type="checkbox"/> bež	EPH3400223



TV/SAT prolazna (8dB)	
Boja	
<input type="checkbox"/> bela	EPH3400321
<input type="checkbox"/> bež	EPH3400323



TV/SAT individualna (1dB)	
Boja	
<input type="checkbox"/> bela	EPH3400421
<input type="checkbox"/> bež	EPH3400423

## Dekoracija



Slepa maska	
Boja	
<input type="checkbox"/> bela	EPH5600121
<input type="checkbox"/> bež	EPH5600123

## Ramovi



2-elementa	
Boja	
<input type="checkbox"/> bela	EPH5800221
<input type="checkbox"/> bež	EPH5800223



3-elementa	
Boja	
<input type="checkbox"/> bela	EPH5800321
<input type="checkbox"/> bež	EPH5800323



4-elementa	
Boja	
<input type="checkbox"/> bela	EPH5800421
<input type="checkbox"/> bež	EPH5800423



5-elemenata	
Boja	
<input type="checkbox"/> bela	EPH5800521
<input type="checkbox"/> bež	EPH5800523



6-elemenata	
Boja	
<input type="checkbox"/> bela	EPH5800621
<input type="checkbox"/> bež	EPH5800623



2-elementa	
Boja	
<input type="checkbox"/> bela	EPH5810221
<input type="checkbox"/> bež	EPH5810223



3-elementa	
Boja	
<input type="checkbox"/> bela	EPH5810321
<input type="checkbox"/> bež	EPH5810323



## Asfora unosi nove boje u vaš život...

**4** nove boje:  
Aluminijum, Antracit,  
Bronza i Čelik



Aluminijum



Čelik




Bronza




Antracit


### Brza i jednostavna instalacija

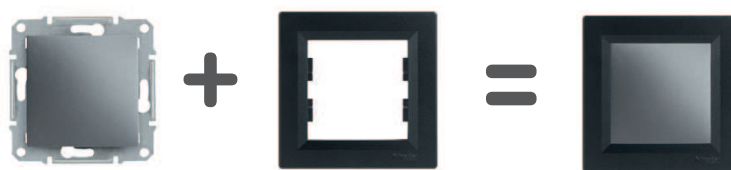Mehanizam sa  
montažnim ramomDekorativni  
ram


## Prekidači 10AX - 250V

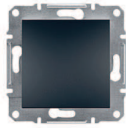


1P	
Boja	
■ antracit	EPH0100371
■ čelik	EPH0100362
■ aluminijum	EPH0100361
■ bronza	EPH0100369

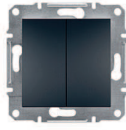


Serijski prekidač	
Boja	
■ antracit	EPH0300371
■ čelik	EPH0300362
■ aluminijum	EPH0300361
■ bronza	EPH0300369

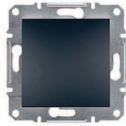


Naizmienični prekidač	
Boja	
■ antracit	EPH0400371
■ čelik	EPH0400362
■ aluminijum	EPH0400361
■ bronza	EPH0400369

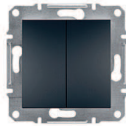

Dvostruki naizmienični prekidač	
Boja	
■ antracit	EPH0600171
■ čelik	EPH0600162
■ aluminijum	EPH0600161
■ bronza	EPH0600169

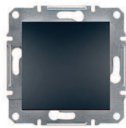

Unakrsni prekidač	
Boja	
■ antracit	EPH0500371
■ čelik	EPH0500362
■ aluminijum	EPH0500361
■ bronza	EPH0500369

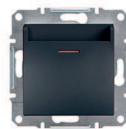

Kartični prekidač	
Boja	
■ antracit	EPH6200171
■ čelik	EPH6200162
■ aluminijum	EPH6200161
■ bronza	EPH6200169

## Tasteri 10AX - 250V



Taster	
Boja	
■ antracit	EPH0800371
■ čelik	EPH0800362
■ aluminijum	EPH0800361
■ bronza	EPH0800369



Taster sa simbolom „zvono“	
Boja	
■ antracit	EPH0800171
■ čelik	EPH0800162
■ aluminijum	EPH0800161
■ bronza	EPH0800169




Taster sa simbolom „svetlo“	
Boja	
■ antracit	EPH0900171
■ čelik	EPH0900162
■ aluminijum	EPH0900161
■ bronza	EPH0900169



Prekidač za roletne	
Boja	
■ antracit	EPH1300371
■ čelik	EPH1300362
■ aluminijum	EPH1300361
■ bronza	EPH1300369

### Prekidač sa lokatorom 10AX - 250V

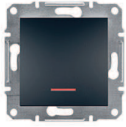

1P sa lampicom	
Boja	
■ antracit	EPH1400371
■ čelik	EPH1400362
■ aluminijum	EPH1400361
■ bronza	EPH1400369



Naizmenični prekidač sa lampicom	
Boja	
■ antracit	EPH1500371
■ čelik	EPH1500362
■ aluminijum	EPH1500361
■ bronza	EPH1500369

### Prekidač sa lokatorom 16AX - 250V



1P	
Boja	
■ antracit	EPH1430371
■ čelik	EPH1430362
■ aluminijum	EPH1430361
■ bronza	EPH1430369

### Tasteri sa lampicom i simbolima 10AX - 250V



Taster sa lampicom	
Boja	
■ antracit	EPH1600371
■ čelik	EPH1600362
■ aluminijum	EPH1600361
■ bronza	EPH1600369



Taster sa lampicom i simbolom „zvono“	
Boja	
■ antracit	EPH1700371
■ čelik	EPH1700362
■ aluminijum	EPH1700361
■ bronza	EPH1700369




Taster sa lampicom i simbolom „svetlo“	
Boja	
■ antracit	EPH1800171
■ čelik	EPH1800162
■ aluminijum	EPH1800161
■ bronza	EPH1800169




Taster sa lampicom i simbolom „stepenice“	
Boja	
■ antracit	EPH1900371
■ čelik	EPH1900362
■ aluminijum	EPH1900361
■ bronza	EPH1900369

## Dimer

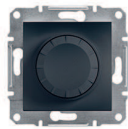


Dimer, RL 40-600VA	
Boja	
■ antracit	EPH6400171
■ čelik	EPH6400162
■ aluminijum	EPH6400161
■ bronza	EPH6400169

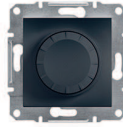

Dimer, RC 20-315VA	
Boja	
■ antracit	EPH6600171
■ čelik	EPH6600162
■ aluminijum	EPH6600161
■ bronza	EPH6600169


## Dimeri sa lokatorom

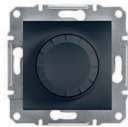


Dimer sa lokatorom, RL 40-600VA	
Boja	
■ antracit	EPH6500171
■ čelik	EPH6500162
■ aluminijum	EPH6500161
■ bronza	EPH6500169

EPH64001..	EPH65001..	EPH66001..	
Osigurač F6.3AH	Elektronska	Zaštita od kratkog spoja	
		Tip opterećenja	
40-600 W	40-600 W	20-315 W	sijalica sa užarenim vlaknom 230 V AC
40-600 W	40-600 W	20-315 W	halogene sijalice 230 V AC
40-600 VA	40-600 VA	-	LV halogene sijalice sa feromagnetskim transformatorom 12 V
-	-	20-315 VA	LV halogene sijalice sa elektronskim transformatorom

## Utičnice 16AX - 250V

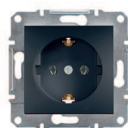

2P+PE	
Boja	
■ antracit	EPH2900171
■ čelik	EPH2900162
■ aluminijum	EPH2900161
■ bronza	EPH2900169

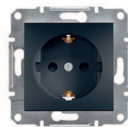

2P+PE sa zaštitom	
Boja	
■ antracit	EPH2900271
■ čelik	EPH2900262
■ aluminijum	EPH2900261
■ bronza	EPH2900269



2P+PE crvena	
Boja	
	EPH2900521



2P+PE sa poklopcem	
Boja	
■ antracit	EPH3100171
■ čelik	EPH3100162
■ aluminijum	EPH3100161
■ bronza	EPH3100169



2P+PE sa poklopcem i zaštitom	
Boja	
■ antracit	EPH3100371
■ čelik	EPH3100362
■ aluminijum	EPH3100361
■ bronza	EPH3100369



Dvostruka 2P+PE (dostupno od januara 2016.)	
Boja	
■ antracit	EPH9900171
■ čelik	EPH9900162
■ aluminijum	EPH9900161
■ bronza	EPH9900169

## Telefonske utičnice



1xRJ11	
Boja	
■ antracit	EPH4100171
■ čelik	EPH4100162
■ aluminijum	EPH4100161
■ bronza	EPH4100169



2xRJ11	
Boja	
■ antracit	EPH4200171
■ čelik	EPH4200162
■ aluminijum	EPH4200161
■ bronza	EPH4200169


## Komunikacione utičnice



1xRJ45, kat. 5e UTP	
Boja	
■ antracit	EPH4300171
■ čelik	EPH4300162
■ aluminijum	EPH4300161
■ bronza	EPH4300169



2xRJ45, kat. 5e UTP	
Boja	
■ antracit	EPH4400171
■ čelik	EPH4400162
■ aluminijum	EPH4400161
■ bronza	EPH4400169

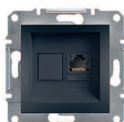


1xRJ45, kat. 6 UTP	
Boja	
■ antracit	EPH4700171
■ čelik	EPH4700162
■ aluminijum	EPH4700161
■ bronza	EPH4700169



2xRJ45, kat. 6 UTP	
Boja	
■ antracit	EPH4800171
■ čelik	EPH4800162
■ aluminijum	EPH4800161
■ bronza	EPH4800169

## Utičnica za zvučnike

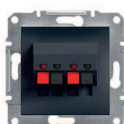

Utičnica za zvučnike	
Boja	
■ antracit	EPH5700171
■ čelik	EPH5700162
■ aluminijum	EPH5700161
■ bronza	EPH5700169



## TV, TV/R, TV/SAT utičnice



TV završna (1dB)	
Boja	
■ antracit	EPH3200171
■ čelik	EPH3200162
■ aluminijum	EPH3200161
■ bronza	EPH3200169



TV/R završna (1dB)	
Boja	
■ antracit	EPH3300171
■ čelik	EPH3300162
■ aluminijum	EPH3300161
■ bronza	EPH3300169



TV/R prolazna (4dB)	
Boja	
■ antracit	EPH3300271
■ čelik	EPH3300262
■ aluminijum	EPH3300261
■ bronza	EPH3300269



TV/R prolazna (8dB)	
Boja	
■ antracit	EPH3300371
■ čelik	EPH3300362
■ aluminijum	EPH3300361
■ bronza	EPH3300369



TV/SAT završna (1dB)	
Boja	
■ antracit	EPH3400171
■ čelik	EPH3400162
■ aluminijum	EPH3400161
■ bronza	EPH3400169



TV/SAT prolazna (4dB)	
Boja	
■ antracit	EPH3400271
■ čelik	EPH3400262
■ aluminijum	EPH3400261
■ bronza	EPH3400269



TV/SAT prolazna (8dB)	
Boja	
■ antracit	EPH3400371
■ čelik	EPH3400362
■ aluminijum	EPH3400361
■ bronza	EPH3400369











TV/SAT individualna (1dB)	
Boja	
■ antracit	EPH3400471
■ čelik	EPH3400462
■ aluminijum	EPH3400461
■ bronza	EPH3400469



Slepa maska	
Boja	
■ antracit	EPH5600171
■ čelik	EPH5600162
■ aluminijum	EPH5600161
■ bronza	EPH5600169

## Dekoracija

## Ramovi

	<b>1-element</b>		
	Boja		
	■ antracit	EPH5800171	
	■ čelik	EPH5800162	
	■ aluminijum	EPH5800161	
		■ bronza	EPH5800169
	<b>2-elementa</b>		
	Boja		
	■ antracit	EPH5800271	
	■ čelik	EPH5800262	
	■ aluminijum	EPH5800261	
		■ bronza	EPH5800269
	<b>3-elementa</b>		
	Boja		
	■ antracit	EPH5800371	
	■ čelik	EPH5800362	
	■ aluminijum	EPH5800361	
		■ bronza	EPH5800369
	<b>4-elementa</b>		
	Boja		
	■ antracit	EPH5800471	
	■ čelik	EPH5800462	
	■ aluminijum	EPH5800461	
		■ bronza	EPH5800469
	<b>5-elemenata</b>		
	Boja		
	■ antracit	EPH5800571	
	■ čelik	EPH5800562	
	■ aluminijum	EPH5800561	
		■ bronza	EPH5800569
	<b>6-elemenata</b>		
	Boja		
	■ antracit	EPH5800671	
	■ čelik	EPH5800662	
	■ aluminijum	EPH5800661	
		■ bronza	EPH5800669
	<b>2-elementa</b>		
	Boja		
	■ antracit	EPH5810271	
	■ čelik	EPH5810262	
	■ aluminijum	EPH5810261	
		■ bronza	EPH5810269
	<b>3-elementa</b>		
	Boja		
	■ antracit	EPH5810371	
	■ čelik	EPH5810362	
	■ aluminijum	EPH5810361	
		■ bronza	EPH5810369