




BBV5191800

Altivar

VW3A7723, VW3A7724



		W	
	Ω	40°C / 104°F	
VW3A7723	100	32	ATV12●●●●F1, ATV12H018M2...ATV12HU15M2, ATV12H018M3...ATV12HU15M3, ATV12P037M2...ATV12P075M2, ATV12P037M3...ATV12PU15M3,
VW3A7724	68	32	ATV12HU22M2, ATV12HU22M3, ATV12PU22M3

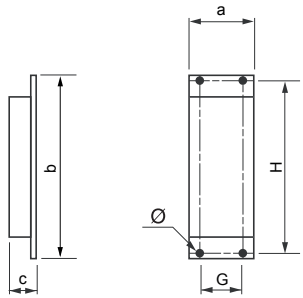

	a	b	c	G	H	Ø
VW3 A7 723	60	170	30	40	154	5
VW3 A7 724	(2.36)	(6.69)	(1.18)	(1.57)	(6.06)	(0.20)

