
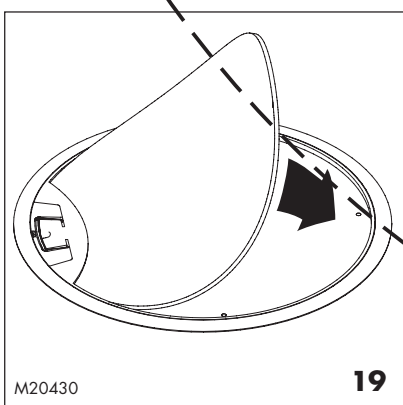
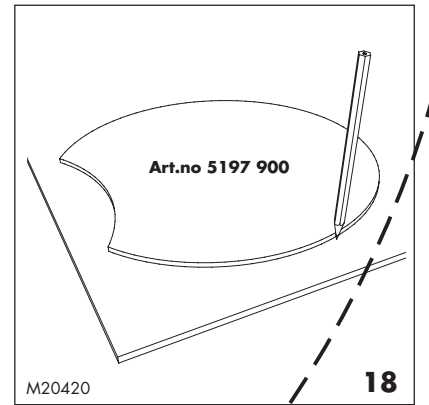
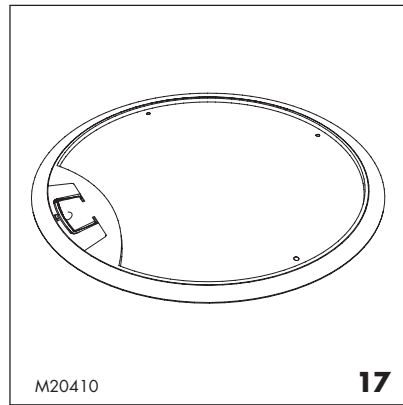
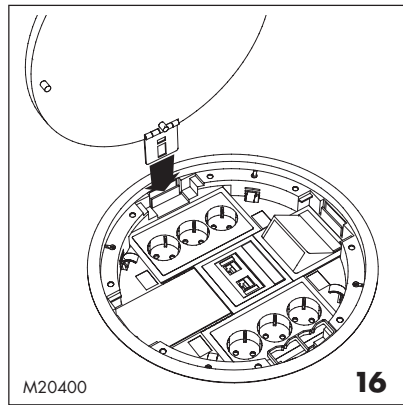
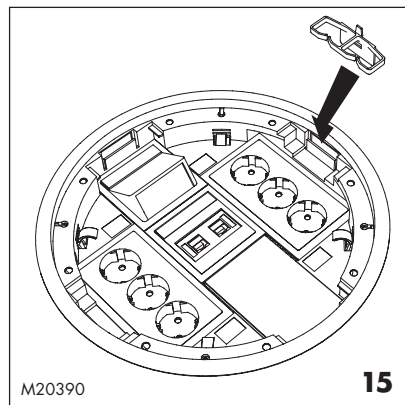
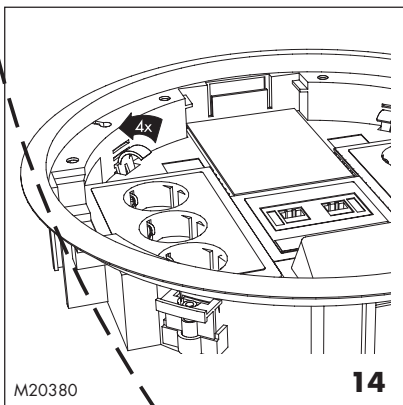
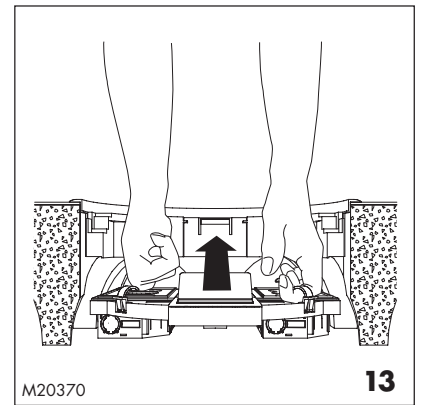
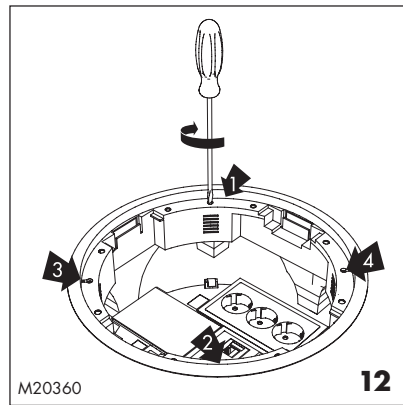
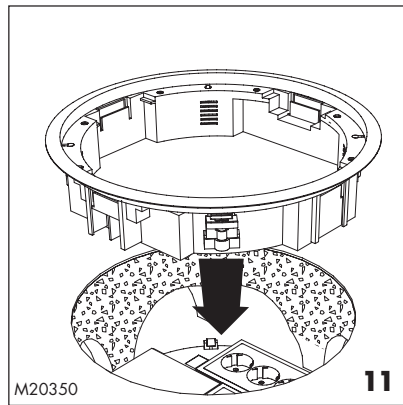
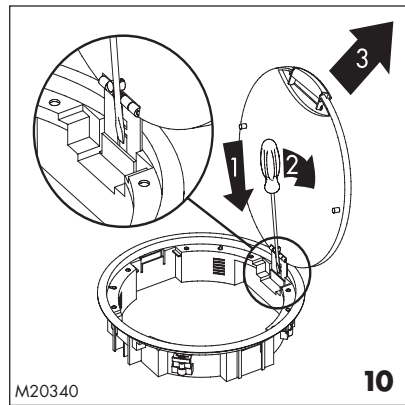
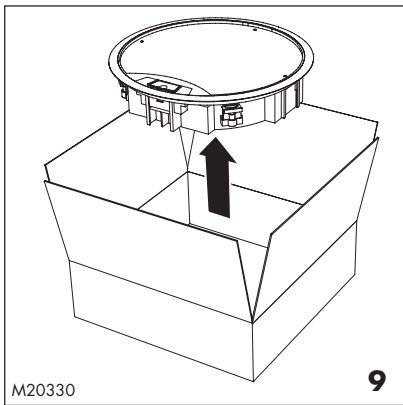
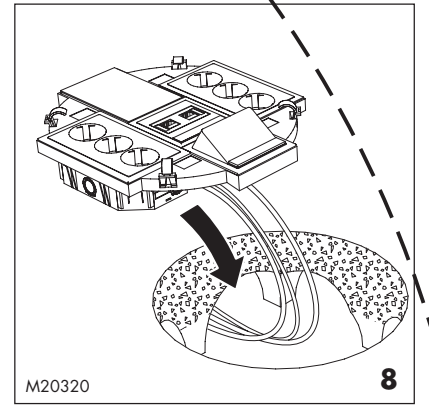
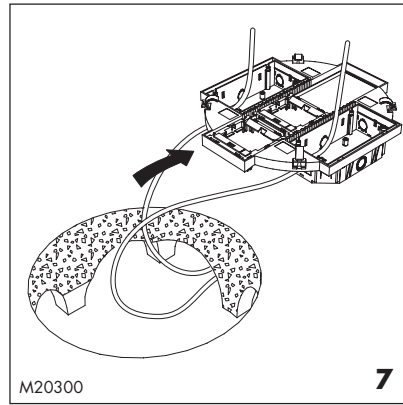
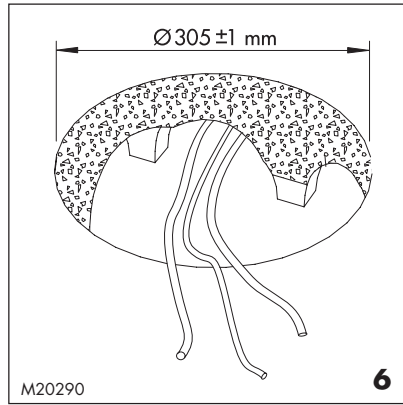
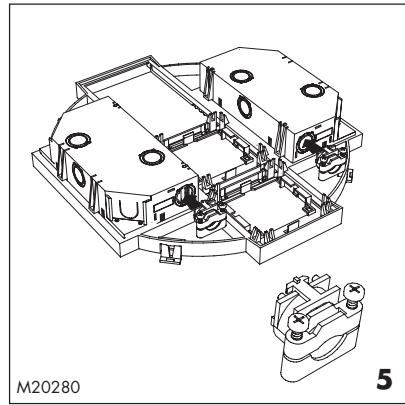
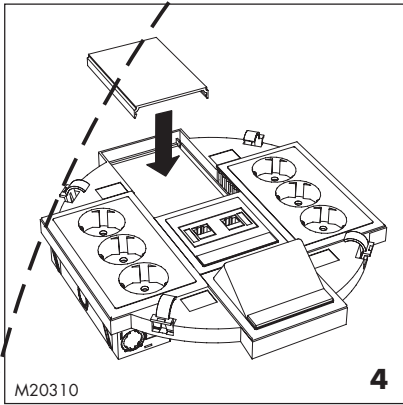
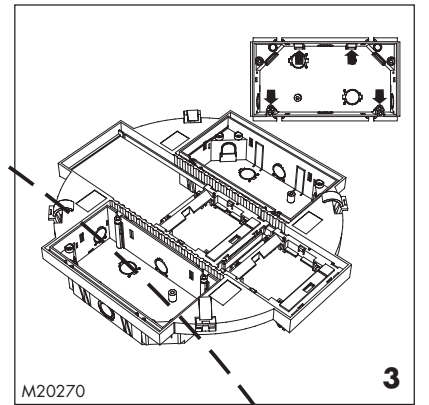
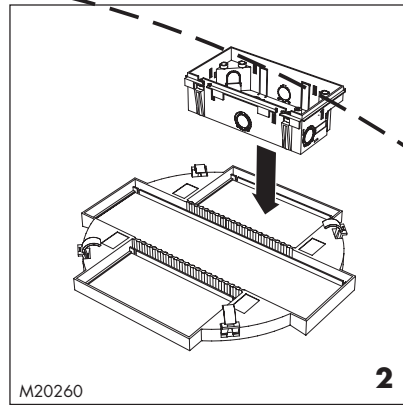
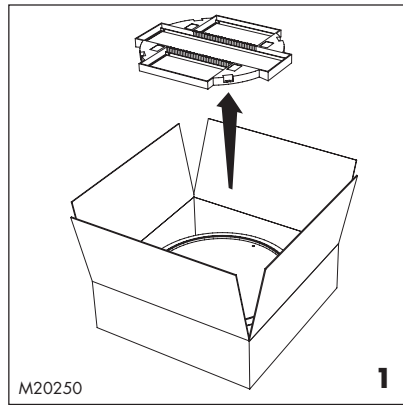


UFB-800

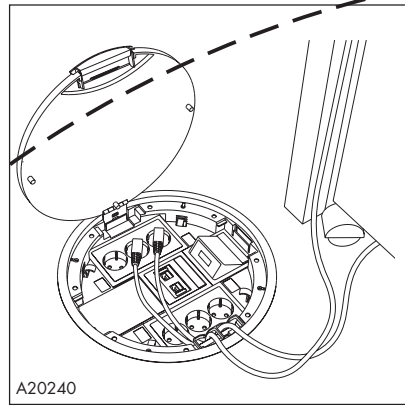

~ 230/400V 16A

| A   | B  | H  | L  | H  | H <sub>1</sub> = 30 |
|-----|----|----|----|----|---------------------|
| 70  | 15 | 32 | 70 | -  | -                   |
| 75  | 20 | 37 | 70 | -  | -                   |
| 80  | 25 | 42 | 70 | 42 | -                   |
| 85  | 30 | 47 | 70 | 47 | 30                  |
| 90  | 35 | 52 | 70 | 52 | 35                  |
| 95  | 40 | 57 | 70 | 57 | 40                  |
| 100 | 45 | 62 | 70 | 62 | 45                  |