


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

9001KA2G

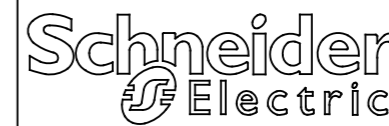

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL File: E78403 CCN NKCR
 CSA File: LR24590 Class 3211-03
 CE Marked: Yes
 RoHS compliant: Yes
 NEMA / IP Rating: n/a
 Max. Voltage Rating: 600V

Specification:

Description:
 Ampere Rating: 10A
 Contact Configuration: 1 NO
 Contact Type: Series G Style (Not Fingersafe)
 Terminal Type: Screw Clamp (Ring Tongue compatible)