


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**9001KA6**

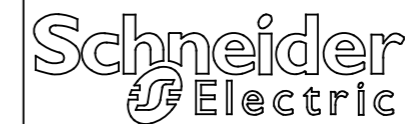

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

UL File: E78403 CCN NKCR  
 CSA File: LR24590 Class 3211-03  
 CE Marked: Yes  
 RoHS compliant: Yes  
 NEMA / IP Rating: IP20  
 Max. Voltage Rating: 600V

**Description:**  
 Ampere Rating: 10A  
 Contact Configuration: 1 NO (Early Close)  
 Contact Type: Standard (Fingersafe)  
 Terminal Type: Screw Clamp

**Specification:**