


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**ABL8BUF24400**

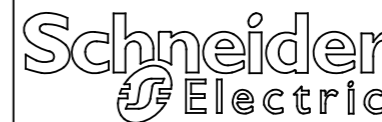

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Wire Range: #6 - #16  
 Tightening Torque: <=12AWG, 10 lb-in (1.2Nm); >12AWG, 18 lb-in (2Nm)  
 Mounting: DIN Rail  
 Screw for Panel Mtg.: N/A  
 Weight: 3 lb (1.36 kg)  
 UL File: E164867 NMTR, E164867 NMTR7  
 CSA File: 238438 5311-07, 238438 5311-87  
 Conform to EN61000-3-2: Yes  
 CE: Yes  
 RoHS: Yes

**Specification:**

Description: Function Modules  
 Type: 40 Amp Buffer Module  
 Input Voltage: 24Vdc  
 Output Voltage: 24Vdc  
 Nominal Power:  
 Nominal Current: 40 Amp  
 Reset: