


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ABL8DCC12020

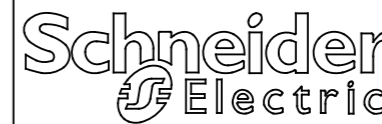

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Wire Range: #12 - #20
 Tightening Torque: ≤12AWG, 10 lb-in (1.2Nm); >12AWG, 18 lb-in (2Nm)
 Mounting: DIN Rail
 Screw for Panel Mtg.: N/A
 Weight: 0.66 lb (0.30 kg)
 UL File: E164867 NMTR, E164867 NMTR7
 CSA File: 238438 5311-07, 238438 5311-87
 Conform to EN61000-3-2: Yes
 CE: Yes
 RoHS: Yes

Specification:

Description: Function Modules
 Type: 2 Amp DC/DC Converter Module
 Input Voltage: 24 Vdc to 28.8 Vdc
 Output Voltage: 7 - 15Vdc
 Nominal Power:
 Nominal Current: 2 Amp
 Reset: