


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ABL8RPS24100

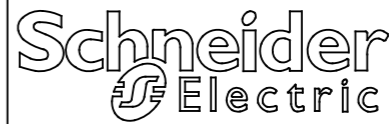

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Wire Range: #8 - #22
 Tightening Torque: <=12AWG, 10.63 lb-in (1.2Nm); >12AWG, 17.71 lb-in (2Nm)
 Mounting: DIN Rail
 Screw for Panel Mtg.: N/A
 Weight: 2.20 lb (1.00 kg)
 UL File: E164867 NMTR, E164867 NMTR2, E164867 NMTR7, E164867 NMTR8
 CSA File: 238438 5311-07, 238438 5311-87
 Conform to EN61000-3-2: Yes
 CE: Yes
 RoHS: Yes

Specification:

Description: Universal Power Supplies
 Type: Power Supply 24Vdc 10 Amp
 Input Voltage: 100-120 or 200-500 -15/+10% 50/60Hz, single phase
 Output Voltage: 24Vdc
 Nominal Power: 240 Watts
 Nominal Current: 10 Amp
 Reset: Automatic or Manual