


AR100

NetShelter WX 13U c/Orifício Roscado, Porta Dianteira Vidrada em Guia de Montagem Vertical, em Preto

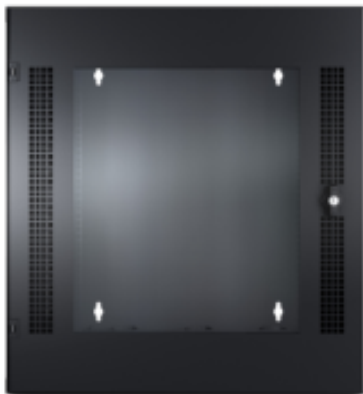

Visão geral

Apresentação	Ideal for retail, healthcare, and educational facilities, the wall rack offers an efficient solution for deploying server and networking equipment for edge computing applications. For areas with limited floor space. Designed to house your server, as well as network solutions such as network switches and patch panels. Rack hinges at the rear allowing for access to the back of the rack during installation and setup or while undergoing maintenance. The door is reversible allowing for the door to open direction desired to avoid interference with its surroundings. Optional 120V fan tray top-mounted and caster kit. Several APC Smart-UPS models low-profile provide easy UPS integration and mounting. 13U Wall mount cabinet, 19 inches maximum mounting depth, 200lb weight-capacity, 19" rack width, ships fully assembled, glass door, 5 year APC warranty.
Prazo de entrega	Normalmente em stock

Geral

Equipamento fornecido	Tecla(S) Manual do utilizador Guia de montagem de parede
-----------------------	--

Físico

Cor	Preto
Profundidade	63,1 Cm
Altura	66,3 Cm
Profundidade de montagem máxima	48,26 Cm
Marking	16 gauge EIA mounting rail 16 gauge porta da frente 16 gauge post 13 gauge rear door 18 gauge roof 18 gauge side panels
Peso net	42,73 Kg
Número de unidade de bastidor	13U
Rack width	19"
Carga admissível permanente	90,72 Kg estático
Largura	58,4 Cm

Conformidades

Normas	EIA-310E
--------	----------

Unidades de embalagem

Peso da embalagem (Lbs)	52,27 Kg
Pacote 1 Altura	83,8 Cm
Pacote 1 largura	68,6 Cm
Pacote 1 Comprimento	77,5 Cm

Sustentabilidade da oferta

Situação da oferta sustentável	Produto Green Premium
Regulamento REACH	Declarção REACH
REACH sem SVHC	Sim
Diretiva RoHS da UE	Conformidade proativa (Produto fora do âmbito RoHS da UE) Declarção-RoHS da EU
Sem metais pesados tóxicos	Sim
Sem mercúrio	Sim
Informações das isenções RoHS	Sim
Take-back	Take-back program available

Garantia contractual

Garantia	Reparar ou substituir 5 anos
----------	------------------------------

Product Life Status : **Comercializado**