

Product data sheet


Characteristics

AZ5CE010

Cable ends, Lineryg TR cable ends, single conductor, red, 1mm², medium size, 5 sets of 200

Product availability: Stock - Normally stocked in distribution facility

Price*: 0.18 USD

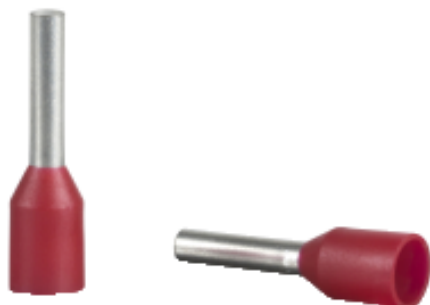

Main

| | |
|---------------------------|--|
| Range of Product | Lineryg |
| Product or Component Type | Cable end |
| Cable end size | Medium |
| Standards | NF C 63-023 |
| Type of Packing | Dispenser pack |
| Quantity per Set | 5 sets of 200 |
| Cable cross section | 0.002 In ² (1 mm ²) |

Complementary

| | |
|------------------------|---------------------------|
| Cable end type | Single conductor |
| Additional information | Without marker tag holder |
| Color | Red |
| Bezel material | Halogen-free plastic |
| Tube material | Copper ISO 1337 |
| Number of cables | 1 |
| AWG Gauge | 18 AWG |
| Bezel size | Ø 3.5 mm |
| Tube diameter | 0.07 In (1.7 mm) |
| Length | 0.6 In (14 mm) |
| Tube length | 0.3 In (8 mm) |
| Product Weight | 0.364 Lb(US) (0.165 kg) |

Environment

| | |
|---------------------------------------|----------------------------|
| Product Certifications | UL |
| Ambient Air Temperature for Operation | -4...221 °F (-20...105 °C) |

Ordering and shipping details

| | |
|-------------------|---------------|
| Category | US1000I22621 |
| Discount Schedule | 000I |
| GTIN | 3389110544022 |
| Returnability | Yes |
| Country of origin | DE |

Packing Units

| | |
|------------------------------|--------------------------|
| Unit Type of Package 1 | PCE |
| Nbr. of units in pkg. | 1 |
| Package 1 Height | 0.157 In (0.400 cm) |
| Package 1 Width | 0.157 In (0.400 cm) |
| Package 1 Length | 0.551 In (1.400 cm) |
| Package weight(Lbs) | 0.004 Oz (0.100 g) |
| Unit Type of Package 2 | BB1 |
| Number of Units in Package 2 | 1000 |
| Package 2 Height | 5.118 In (13.000 cm) |
| Package 2 Width | 2.756 In (7.000 cm) |
| Package 2 Length | 4.921 In (12.500 cm) |
| Package 2 Weight | 5.362 Oz (152.000 g) |
| Unit Type of Package 3 | S04 |
| Number of Units in Package 3 | 40000 |
| Package 3 Height | 11.811 In (30.000 cm) |
| Package 3 Width | 15.748 In (40.000 cm) |
| Package 3 Length | 23.622 In (60.000 cm) |
| Package 3 Weight | 15.243 Lb(US) (6.914 kg) |

Environmental data

| | |
|--|---|
| RECh free of SVHC | Yes |
| Toxic heavy metal free | Yes |
| Mercury free | Yes |
| Sustainable packaging | No |
| Environmental Disclosure | Product Environmental Profile |
| Packaging made with recycled cardboard | Yes |
| Packaging without single use plastic | No, we have minimized the use of plastic in the packaging in compliance with regulations and consider |
| RECh Regulation | Free of Substances of Very High Concern above the threshold ↗ |
| EU RoHS Directive | Compliant ↗ |
| Halogen content performance | Halogen free plastic parts product |
| PVC free | Yes |
| Silicon free | Yes |
| Circularity Profile | End Of Life Information |
| Take-back | No |
| WEEE Label | The product must be disposed on European Union markets following specific waste collection and neve |

Contractual warranty

| | |
|----------------------|----|
| Warranty (in months) | 18 |
|----------------------|----|

Product Life Status : **Commercialised**