
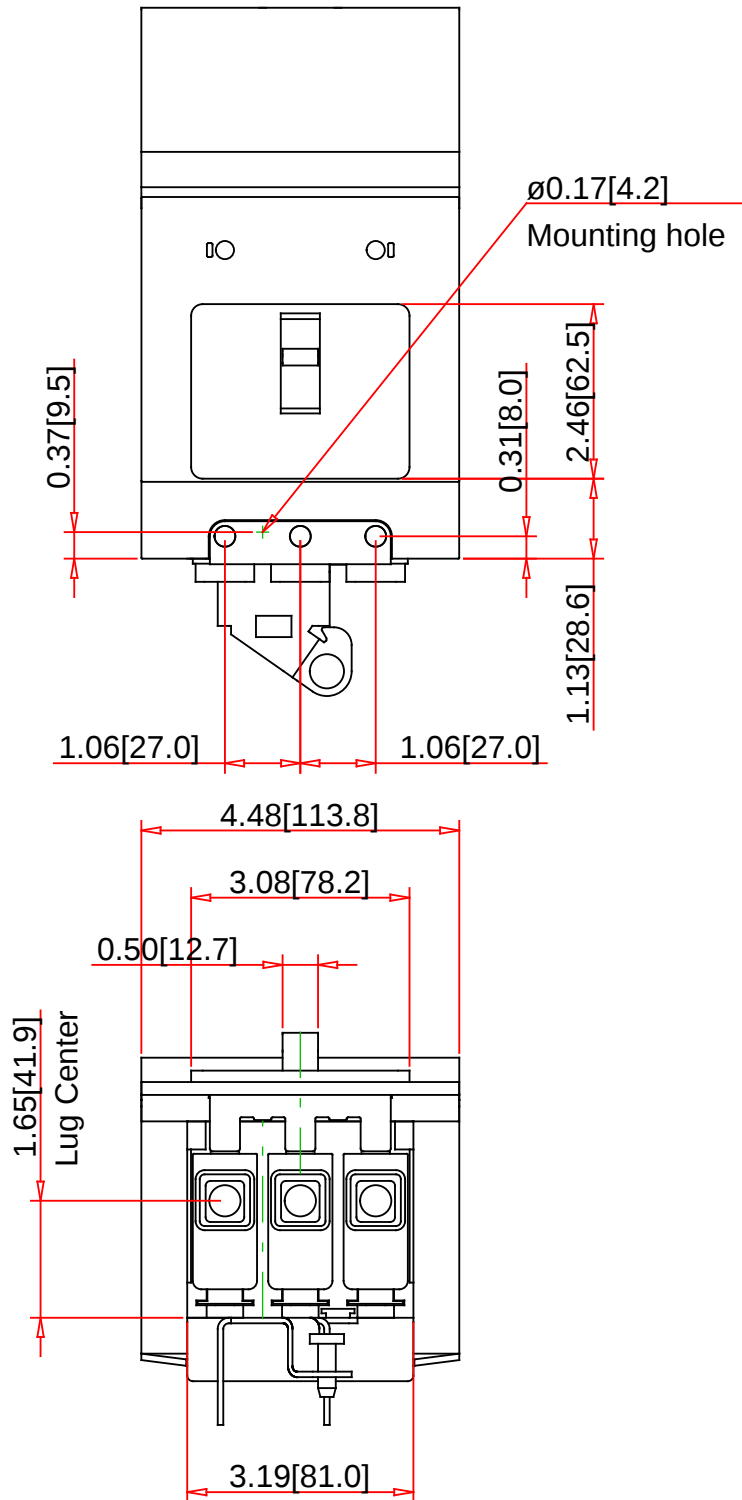


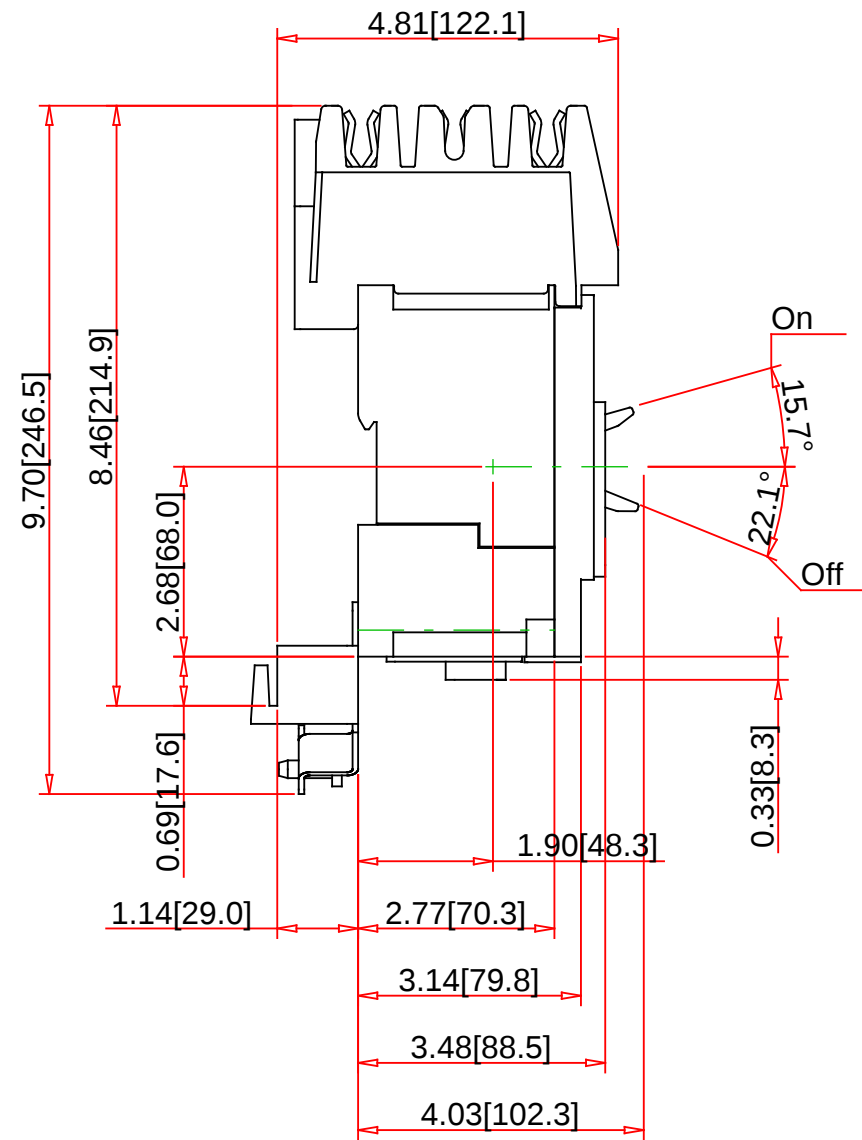

Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

BDA34015Y



by **Schneider Electric**

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 877 342 5173
Email: CCC@us.schneider-electric.com

Technical Information:

General Application: Provides overload and short circuit protection
Approvals: UL Listed - CSA Certified - IEC Rated
Mounting Type: I-Line
Terminal Type: ON end: I-Line / OFF end: Mechanical Lugs
Weight: 3
Depth:
Height:
Width:
Mounting Height: 4.5

Specification:

Description: PowerPact B-Frame Thermal Magnetic Circuit Breaker
Number of Poles: 3-Pole
Ampere Rating: 015
Voltage Rating: 480Y/277 VAC
Interrupting Rating: 25kA at 240VAC 18kA at 480Y/277VAC
Circuit Breaker Rating: 80% Rated
Fixed AC Magnetic Trip: Hold: 320A - Trip: 480A