


Note:  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**BMH0701P06A2A**

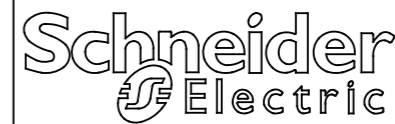

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

Technical Information:

Frame Size (mm): 70  
 Degree of Protection (Shaft / housing): IP54 / IP65  
 Maximum Current (Arms): 5.97  
 Holding brake: No  
 Encoder Type: ABS Single turn 16 Sin/Cos period  
 Torque Constant (Nm/A): 0.79  
 CSA: Yes  
 RoHS: Yes  
 Weight without brake (kg / lb): 3.53 / 1.6

Specification:

Description:  
 Family: BMH  
 Maximum Permissible Speed (rpm): 8000  
 Continuous Stall Torque (Nm / lbs-in): 1.4 / 12.4  
 Peak Torque (Nm / lbs-in): 4.2 / 37.2