


Note:  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**BMH1403P07F2A**

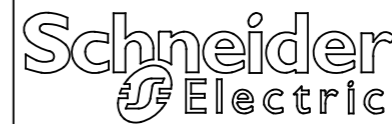

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

Technical Information:

Frame Size (mm): 140  
 Degree of Protection (Shaft / housing): IP54 / IP65  
 Maximum Current (Arms): 62.32  
 Holding brake: Yes  
 Encoder Type: ABS Multi turn 16 Sin/Cos period  
 Torque Constant (Nm/A): 1.33  
 CSA: Yes  
 RoHS: Yes  
 Weight without brake (kg / lb): 35.27 / 16

Specification:

Description:  
 Family: BMH  
 Maximum Permissible Speed (rpm): 4000  
 Continuous Stall Torque (Nm / lbs-in): 24.0 / 212.4  
 Peak Torque (Nm / lbs-in): 75 / 663.8