


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

BMH1903P31F2A

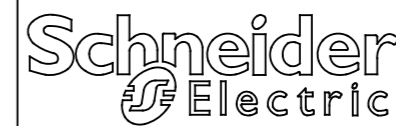

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Frame Size (mm): 190
 Degree of Protection (Shaft / housing): IP65 / I P65
 Maximum Current (Arms): 124.5
 Holding brake: Yes
 Encoder Type: ABS Single turn 128 Sin/Cos period
 Torque Constant (Nm/A): 1.8
 CSA: Yes
 RoHS: Yes
 Weight without brake (kg / lb): 94.80 / 43

Description:
 Family: BMH
 Maximum Permissible Speed (rpm): 3500
 Continuous Stall Torque (Nm / lbs-in): 65 / 575.3
 Peak Torque (Nm / lbs-in): 195 / 1725.9

Specification: