


Note:  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**BMH2053P01A2A**

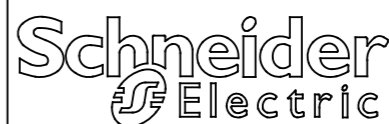

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

Technical Information:

Frame Size (mm): 205  
 Degree of Protection (Shaft / housing): IP54 / IP65  
 Maximum Current (Arms): 107.4  
 Holding brake: No  
 Encoder Type: ABS Single turn 128 Sin/Cos period  
 Torque Constant (Nm/A): 3.5  
 CSA: Yes  
 RoHS: Yes  
 Weight without brake (kg / lb): 147.70 / 67

Description:  
 Family: BMH  
 Maximum Permissible Speed (rpm): 3800  
 Continuous Stall Torque (Nm / lbs-in): 88 / 778.9  
 Peak Torque (Nm / lbs-in): 330 / 2920.7

Specification: