


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

BMXAMI0410

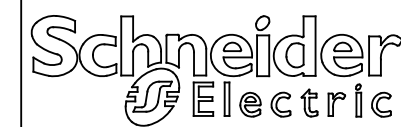

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Mounting: Any slot except 0
 Isolation Between Channels: 1400 VDC
 Isolation Between Channels and Bus: 300 VDC
 UL & CSA: Yes
 CE: Yes
 RoHS: Yes
 Class 1 Div 2 CSA: Yes
 GOST/BV/GL/RMRS/ABS: Yes
 Weight [kg]: 0.143

Specification:

Description:
 Selection: M340 PAC
 Conf.Coating - 25C to 70C op.temp.: No
 Input Voltage Range: ± 10 V, ± 5 V, 0 to 10 V, 0 to 5 V, 1 to 5 V
 Input Current: 0 to 20 mA, 4 to 20 mA, ± 20 mA
 Output Voltage Range:
 Output Current:
 Connection Type: BMXFCA500/BMXFTW301S/BMXFTW501S/ABE7CPA410/BMXFCA150/BMXFCA300
 Number of Inputs: 4
 Number of Outputs: