


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**BMXAMO0210**

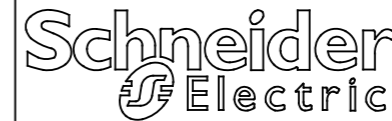

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Mounting:	Any slot except 0
Isolation Between Channels:	750 VDC
Isolation Between Channels and Bus:	1400 VDC
UL & CSA:	Yes
CE:	Yes
RoHS:	Yes
Class 1 Div 2 CSA:	Yes
GOST/BV/GL/RMRS/ABS:	Yes
Weight [kg]:	0.144

**Specification:**

Description:	
Selection:	M340 PAC
Conf.Coating - 25C to 70C op.temp.:	No
Input Voltage Range:	
Input Current:	
Output Voltage Range:	± 10 V
Output Current:	0 to 20 mA, 4 to 20 mA
Connection Type:	BMXFTB2000/BMXFTB2010/BMXFTB2020/BMXFTW301/BMXFTW501/BMXFTW1001
Number of Inputs:	
Number of Outputs:	2