


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**BMXART0414**

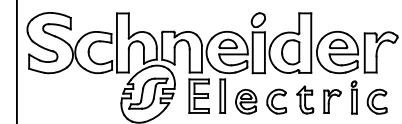

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Mounting:	Any slot except 0
Isolation Between Channels:	1400 VDC
Isolation Between Channels and Bus:	750 VDC
UL & CSA:	Yes
CE:	Yes
RoHS:	Yes
Class 1 Div 2 CSA:	Yes
GOST/BV/GL/RMRS/ABS:	Yes
Weight [kg]:	0.135

**Specification:**

Description:	M340 PAC
Selection:	No
Conf.Coating - 25C to 70C op.temp.:	± 40 mV, ± 80 mV, ± 160 mV, ± 320 mV, ± 640 mV, ± 1.28 V
Input Voltage Range:	0
Input Current:	0
Output Voltage Range:	
Output Current:	
Connection Type:	BMXFCW301S/BMXFCW501S/ABE7CPA412/BMXFCA152/BMXFCA302/BMXFCA502
Number of Inputs:	4
Number of Outputs:	