


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

BMXART0814H

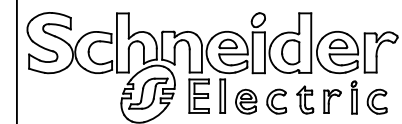

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Mounting:	Any slot except 0
Isolation Between Channels:	1400 VDC
Isolation Between Channels and Bus:	750 VDC
UL & CSA:	Yes
CE:	Yes
RoHS:	Yes
Class 1 Div 2 CSA:	Yes
GOST/BV/GL/RMRS/ABS:	Yes
Weight [kg]:	0.165

Specification:

Description:	M340 PAC
Selection:	Yes
Conf.Coating - 25C to 70C op.temp.:	± 40 mV, ± 80 mV, ± 160 mV, ± 320 mV, ± 640 mV, ± 1.28 V
Input Voltage Range:	0
Input Current:	0
Output Voltage Range:	
Output Current:	
Connection Type:	BMXFCW301S/BMXFCW501S/ABE7CPA412/BMXFCA152/BMXFCA302/BMXFCA502
Number of Inputs:	8
Number of Outputs:	