

# Product data sheet


## Characteristics

# DF2FA100

NFC cartridge fuses, TeSys GS, cylindrical, 22mm x 58mm, fuse type aM, 500VAC, 100A, without striker, set of 10 parts

Product availability: Non-Stock - Not normally stocked in distribution facility

Price\*: 18.60 USD

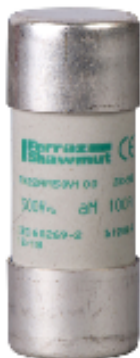

### Main

|                                |                         |
|--------------------------------|-------------------------|
| Range of Product               | TeSys fuse-disconnector |
| Product or Component Type      | Cartridge fuse          |
| Device short name              | DF2                     |
| [Ue] rated operational voltage | 500 V AC                |
| Fuse size                      | 22 x 58 mm              |
| Fuse type                      | NFC                     |
| Quantity per Set               | Set of 10               |

### Complementary

|                    |                        |
|--------------------|------------------------|
| Line Rated Current | 100 A 500 V            |
| Fuse curve         | AM                     |
| Net Weight         | 0.10 Lb(US) (0.045 kg) |

### Ordering and shipping details

|                   |               |
|-------------------|---------------|
| Category          | US1000I22621  |
| Discount Schedule | 000I          |
| GTIN              | 3389110502862 |
| Returnability     | No            |
| Country of origin | TN            |

### Packing Units

|                              |                   |
|------------------------------|-------------------|
| Unit Type of Package 1       | PCE               |
| Number of Units in Package 1 | 1                 |
| Package 1 Height             | 0.94 In (2.4 cm)  |
| Package 1 Width              | 4.65 In (11.8 cm) |
| Package 1 Length             | 4.69 In (11.9 cm) |
| Package 1 Weight             | 1.87 Oz (53.0 g)  |
| Unit Type of Package 2       | BB1               |
| Number of Units in Package 2 | 10                |

|                              |                         |
|------------------------------|-------------------------|
| Package 2 Height             | 0.94 In (2.4 cm)        |
| Package 2 Width              | 4.65 In (11.8 cm)       |
| Package 2 Length             | 4.69 In (11.9 cm)       |
| Package 2 Weight             | 19.12 Oz (542.0 g)      |
| Unit Type of Package 3       | S01                     |
| Number of Units in Package 3 | 120                     |
| Package 3 Height             | 5.91 In (15.0 cm)       |
| Package 3 Width              | 5.91 In (15.0 cm)       |
| Package 3 Length             | 15.75 In (40.0 cm)      |
| Package 3 Weight             | 14.79 Lb(US) (6.707 kg) |

### Offer Sustainability

|                            |  |
|----------------------------|--|
| California proposition 65  | WARNING: Cancer and Reproductive Harm - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>                   |
| REACH Regulation           | <a href="#">REACH Declaration</a>  |
| REACH free of SVHC         | Yes  |
| EU RoHS Directive          | Compliant <a href="#">EU RoHS Declaration</a>  |
| Toxic heavy metal free     | Yes  |
| Mercury free               | Yes  |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>   |
| RoHS exemption information | <a href="#">Yes</a>  |
| WEEE                       | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins. |
| PVC free                   | Yes  |

### Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

Product Life Status : **Commercialised**