

Product data sheet


Characteristics

DZ5CA502

Cable end, Linery TR cable ends, single conductor, blue, medium size, 50 mm², clip-in type, 10 sets of 100

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 2.25 USD

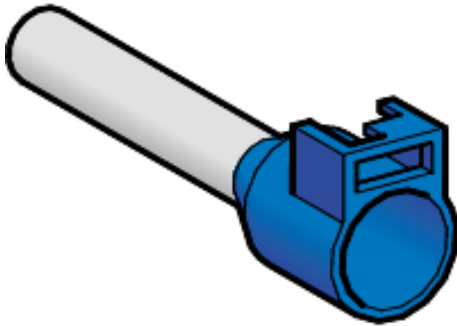

Main

Range of Product	Linery
Product or Component Type	Cable end
Cable end size	Medium
Standards	NF C 63-023
Type of Packing	Bag
Quantity per Set	Set of 20
Cable cross section	0.08 ln ² (50 mm ²)

Complementary

Cable end type	Single conductor
Additional information	For additional marker tag holder
Color	Blue
Bezel material	Halogen-free plastic
Tube material	Copper ISO 1337
Number of cables	1
AWG Gauge	AWG 1/0
Bezel size	Ø 16 mm
Tube diameter	0.43 ln (11 mm)
Length	1.42 ln (36 mm)
Tube length	0.79 ln (20 mm)
CAD overall depth	1.42 ln (36 mm)
Net Weight	0.13 Lb(US) (0.06 kg)

Environment

Ambient air temperature for operation	-4...221 °F (-20...105 °C)
---------------------------------------	----------------------------

Ordering and shipping details

Category	US1000I22621
Discount Schedule	000I
GTIN	3389110535471
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.16 In (0.400 cm)
Package 1 Width	0.16 In (0.400 cm)
Package 1 Length	0.55 In (1.400 cm)
Package 1 Weight	0.11 Oz (3.000 g)
Unit Type of Package 2	BB1
Number of Units in Package 2	20
Package 2 Height	1.57 In (4.000 cm)
Package 2 Width	2.36 In (6.000 cm)
Package 2 Length	5.12 In (13.000 cm)
Package 2 Weight	2.22 Oz (63.000 g)
Unit Type of Package 3	S04
Number of Units in Package 3	2000
Package 3 Height	11.81 In (30.000 cm)
Package 3 Width	15.75 In (40.000 cm)
Package 3 Length	23.62 In (60.000 cm)
Package 3 Weight	15.70 Lb(US) (7.120 kg)

Offer Sustainability

REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.
PVC free	Yes
Halogen content performance	Halogen free plastic parts product

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status : **Commercialised**