

Product data sheet

Characteristics


GV2G445

Linergy FT, Comb busbar, 63A, 4 tap-offs, 45mm pitch



Product availability: Stock - Normally stocked in distribution facility

Price*: 34.20 USD

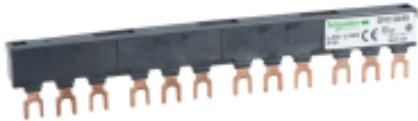

Main

Range	Linergy
Product name	FT
Device short name	GV2G
Product or Component Type	Comb busbar
Accessory / separate part category	Connection accessory
Poles description	3P
Range compatibility	TeSys Deca TeSys GV2 TeSys K TeSys U
Number of tap-offs	4
[Ith] conventional free air thermal current	63 A
Connection pitch	1.77 In (45 mm)

Complementary

Mounting Location	On terminal
[Ui] Rated Insulation Voltage	690 V
Length	7.05 In (179 mm)
Net Weight	0.17 Lb(US) (0.077 kg)

Ordering and shipping details

Category	US10I1122367
Discount Schedule	0I11
GTIN	3389110555882
Returnability	Yes
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	0.39 In (1.000 cm)
Package 1 Width	1.38 In (3.500 cm)
Package 1 Length	7.09 In (18.000 cm)
Package 1 Weight	2.75 Oz (78.000 g)
Unit Type of Package 2	S01
Number of Units in Package 2	60
Package 2 Height	5.91 In (15.000 cm)
Package 2 Width	5.91 In (15.000 cm)
Package 2 Length	15.75 In (40.000 cm)
Package 2 Weight	10.87 Lb(US) (4.930 kg)
Unit Type of Package 3	P06
Number of Units in Package 3	1920
Package 3 Height	29.53 In (75.000 cm)
Package 3 Width	23.62 In (60.000 cm)
Package 3 Length	31.50 In (80.000 cm)
Package 3 Weight	364.78 Lb(US) (165.460 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------

Sets of Busbars GV2G445, GV2G454, GV2G472, with Terminal Block GV2G05

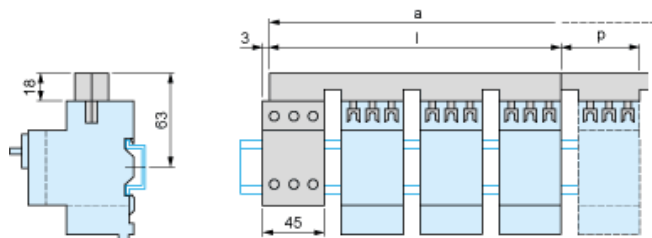

	l	p
GV2G445 (4 x 45 mm)	179	45
GV2G454 (4 x 54 mm)	206	54
GV2G472 (4 x 72 mm)	260	72

Number of tap-offs	a			
	5	6	7	8
GV2G445	224	269	314	359
GV2G454	260	314	368	422
GV2G472	332	404	476	548

Product Life Status : **Commercialised**