


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**NSYEBAP12614**

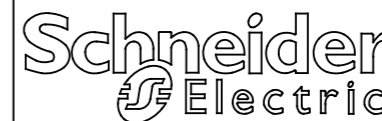

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Copper or Aluminum Wire  
 0.29  
 6 mm Hex  
 5 mm Hex  
 E323110 QPQS  
 N/A  
 File 70361, Class 6228-01 (With wire classes B&C)  
 Yes  
 Yes  
 Yes  
 UL 94 V0

**Description:**  
**Mounting:**  
**Ampere Rating:**  
**Max. Voltage Rating:**  
**Terminal Material:**  
 Wire Range - Line Side AWG/kcmil:  
 Wire Range - Load Side AWG/kcmil:  
 Short Circuit Current Ratings with Fuses:

**Specification:**

Enclosed Power Distribution Block  
 Panel  
 200 Amps CU / 155 Amps AL  
 600V AC/DC  
 Tin Plated Aluminum  
 14 - 3/0 CU / 6 - 3/0 AL  
 14 - 2 CU / 6 - 2 AL  
 Up to 100kA

Type Wire:  
 Weight (lb):  
 Terminal Screw Driver Line Side:  
 Terminal Screw Driver Load Side:  
 UL Listed:  
 UL Recognized:  
 CSA File:  
 RoHS:  
 CE Marked:  
 IP20 Touch Protection from the Front  
 Flammability Rating: