


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

NSYEBAP13618

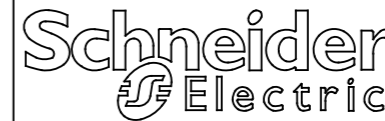

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 8773425173
Email: CCC@us.schneider-electric.com

Technical Information:

Copper or Aluminum Wire
0.77
8 mm & 6 mm Hex
5 mm Hex
N/A
E60616 XCFR2
File 70361, Class 6228-01 (With wire classes B&C)
Yes
Yes
Yes
UL 94 V0

Description:
Mounting:
Ampere Rating:
Max. Voltage Rating:
Terminal Material:
Wire Range - Line Side AWG/kcmil:
Wire Range - Load Side AWG/kcmil:
Short Circuit Current Ratings with Fuses:

Specification:

Enclosed Power Distribution Block
Panel
335 Amps CU / 270 Amps AL
600V AC/DC
Tin Plated Aluminum
6 - 400 & 14 - 3/0 CU / 6 - 400 & 6 - 3/0 AL
14 - 2 CU / 6 - 2 AL
Up to 100kA

Type Wire:
Weight (lb):
Terminal Screw Driver Line Side:
Terminal Screw Driver Load Side:
UL Listed:
UL Recognized:
CSA File:
RoHS:
CE Marked:
IP20 Touch Protection from the Front
Flammability Rating: