


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

T02DN23G7

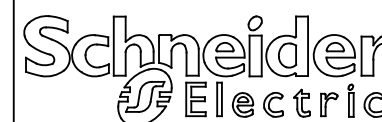

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Max. Continuous Current Rating: 600V / 45A
 Certifications: UL Listed, CSA, CE
 RoHS: Yes
 Termination Method: Everlink Screw Clamp
 Weight (lbs): 4.56
 Power Wire Size (AWG): #4 - #16
 Control Wire Size (AWG): #12 - #16
 Mounting: 35mm DIN Rail, Panel

Specification:

Description: TeSys N Rev. Contactor Sz2 3P 120VAC
 Type: FVR
 Voltages Code: G7 at 120VAC

Coil Consumption: Inrush 160 VA
 Sealed 15 VA

Single Phase			Three Phase		
115V	230V	200V	230V	460V	575V
3 HP	7.5 HP	10 HP	15 HP	25 HP	25 HP