


**Note:**

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

**T02GN13G7**

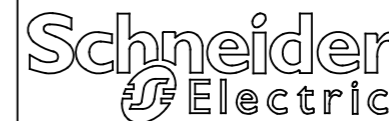

Schneider Electric United States  
North American Division  
Boston One Campus  
800 Federal Street  
Andover, MA 01810, USA  
Phone: +1 8773425173  
Email: CCC@us.schneider-electric.com

**Technical Information:**

Max. Continuous Current Rating: 600V / 270A  
 Certifications: UL Listed, CSA, CE  
 RoHS: Yes  
 Termination Method: Power Circuit: Bar, Control Circuit: Screw Clamp  
 Weight (lbs): 20.52  
 Power Wire Size (AWG): NA  
 Control Wire Size (AWG): #12 - #16  
 Mounting: Panel

**Specification:**

Description: TeSys N Contactor Sz5 3P 120VAC  
 Type: FVNR  
 Voltages Code: G7 at 120VAC  
 Coil Consumption: Inrush 650 VA  
 Sealed 10 VA

Three Phase			
200V	230V	460V	575V
75 HP	100 HP	200 HP	200 HP