


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

T02HN13F7

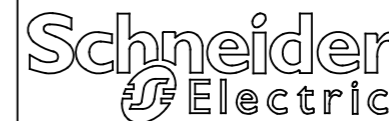

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Max. Continuous Current Rating: 600V / 540A
 Certifications: UL Listed, CSA, CE
 RoHS: Yes
 Termination Method: Power Circuit: Bar, Control Circuit: Screw Clamp
 Weight (lbs): 25.83
 Power Wire Size (AWG): NA
 Control Wire Size (AWG): #12 - #16
 Mounting: Panel

Specification:

Description: TeSys N Contactor Sz6 3P 120VAC
 Type: FVNR
 Voltages Code: F7 at 120VAC
 Coil Consumption: Inrush 1100 VA
 Sealed 18 VA

Three Phase			
200V	230V	460V	575V
150 HP	200 HP	400 HP	400 HP