


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

XPSABV1133P

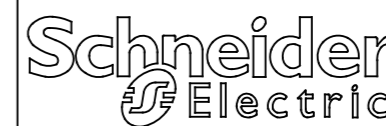

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL File/CCN: E164353 / NKCR
 CSA File/Class: LR44087 / 3211 03
 CE: Yes
 RoHS: Yes

Description:
 Voltage: 24 VDC
 Terminal Type: Screw
 Terminal Block: Fixed
 Safety Contacts - Standard: 2
 Safety Contacts - Time Delay: 1
 Auxiliary Contacts:
 Solid State Outputs:
 Timing Range: 0.15 - 3 s

Specification: