


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

XVBC9M

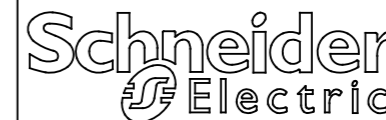

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL File: E164353 CCN NKCR
 CSA File: LR44087 Class 3211-03
 CE Marked: Yes
 RoHS compliant: Yes
 NEMA / IP Rating: NEMA 4X/12 - IP65

Specification:

Description:
 Size: 70mm diameter
 Housing Color: Black
 Lens Color: not applicable
 Bulb Color: not applicable
 Supply Voltage: 120/230V AC
 Signaling Effect: Buzzer (70 to 90 dB adjustable)
 Mounting Type: Integrated Locking Ring
 Terminal Type: Screw Clamp
 Cable Length:
 Comments: includes integral strobe - do not order separate bulb