


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

XVC6M55SK

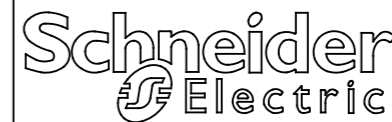

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL File: E164353 CCN NKCR
 CSA File: LR44087 Class 3211-03
 CE Marked: Yes
 RoHS compliant: Yes
 NEMA / IP Rating: NEMA 3R/12 - IP 54

Specification:

Description:
 Size: 60mm diameter
 Housing Color: Red, Orange, Green, Blue and Clear
 Lens Color: Red, Orange, Green, Blue and Clear
 Bulb Color:
 Supply Voltage: 100-240V AC/DC
 Signaling Effect: Steady or Flashing Light (Integral LED) with buzzer
 Mounting Type: Base
 Terminal Type:
 Cable Length: 850mm
 Comments: Pre-Wired and Pre-Assembled