


**Note:**

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

**Part No.:**

**XVUC29**

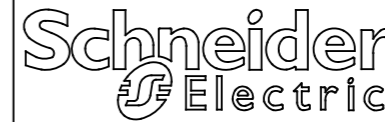

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Agency Approvals: UL, CSA, CE, RoHS  
 Ingress Protection: IP 65  
 Rated Voltage: 24V AC/DC  
 Power Consumption: 70 mA Max.  
 Sound Level :  
 Frequency of Buzzer:  
 Color of Lights: Red, Amber, Yellow, Green, Blue, White  
 Light Source: LED  
 Frequency of Flashing Lights: Blinking slow: 1Hz, Flashing fast 1: 0.23Hz, Flashing fast 2: 7.26Hz, Routing slow: 2.33Hz, Routing fast : 3.3Hz  
 El. Shock Res. EN/IEC 61140:  
 Storage Temperature: -40~+70°C  
 Operating Temperature: -25~+50°C

**Specification:**

Description: 60mm Tower Multi - LED Unit 24VAC/DC  
 Material - Lens Unit: PC(UL94 V-2)  
 Material - closure plate: PC(UL94 V-0)  
 Material - Body:  
 Material - Pole:  
 Material -terminal cover: