


Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

XVUC9SQ

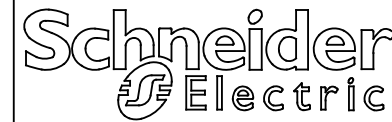

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Agency Approvals: UL, CSA, CE, RoHS
 Ingress Protection: IP 54
 Rated Voltage: 24V AC/DC
 Power Consumption: 70 mA Max.
 Sound Level: 85dB(at 1m)
 Frequency of Buzzer: 2635Hz
 Color of Lights:
 Light Source:
 Frequency of Flashing Lights:
 El. Shock Res. EN/IEC 61140:
 Storage Temperature: -40~+70°C
 Operating Temperature: -25~+50°C

Specification:

Description: 60mm Tower Buzzer Unit - Silver 24VAC/DC
 Material - Lens Unit:
 Material - closure plate: PC(UL94 V-0)
 Material - Body: PBT + ABS(UL94 V-0)
 Material - Pole:
 Material -terminal cover: