


**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**XVUZ800**

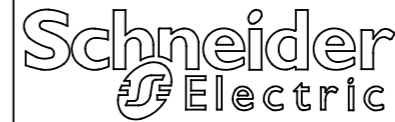

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Agency Approvals: UL, CSA, CE, RoHS  
 Ingress Protection: IP 65  
 Rated Voltage:  
 Power Consumption:  
 Sound Level :  
 Frequency of Buzzer:  
 Color of Lights:  
 Light Source:  
 Frequency of Flashing Lights:  
 El. Shock Res. EN/IEC 61140:  
 Storage Temperature: -40~+70°C  
 Operating Temperature: -25~+50°C

**Specification:**

Description: 60mm Tower Mounting Base with 800mm Black Tube  
 Material - Lens Unit:  
 Material - closure plate: PC(UL94 V-0)  
 Material - Body: PBT + ABS(UL94 V-0)  
 Material - Pole: Aluminum  
 Material -terminal cover: