


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

ZARB18W

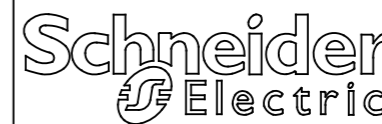

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Inputs: 18 digital (12 Limiters + 6 Alarm)
 Outputs: 20 (18 relay + 2 safety relay)
 Communication: Wireless : Bluetooth low energy
 Operating Frequency: 2.4GHz
 Typical Sensing Distance (Ind. Set.): 50m
 Maximum Sensing Distance: 100m (unobstructed)

Description:
 IP Protection:
 Operating Temperature.:
 Storage Temperature:
 Electrical Durability:
 Mechanical Durability:

Specification:

BASE 18 RELAYS PLUS 2 SAFE WIRE CONNECTION
 IP65
 For 24...130V ac/dc: -25...+70C, For 130...240V ac/dc: -25...+50C
 100,000 cycles
 1,000,000 cycles