


Ø 0.88 +0.02 (Ø 0.89 recommended)
[Ø 22.3 +0.4 (Ø 22.5 recommended)]

Note:
 - Drawings Not To Scale
 - Drawings Subject to Change Without Notice
 - Dimensions are inches next to [Millimeters]

Part No.:

ZB4BK1743

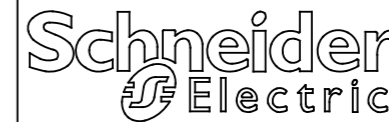

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

UL Listed: Yes
 UL File: E164353 CCN NKCR
 CSA Approval: Yes
 CSA File: LR44087 Class 3211 03
 CE: Yes
 RoHS: Yes
 Bezel Material: Chromed Zinc
 NEMA / IP Rating: NEMA 1/2/3/4/4X/13; IP66
 Key Number: n/a
 Key Removal: n/a
 Max. # of Contact Blocks: 4
 Button Marking: none

Specification:

Description: 22mm 3 Pos Selector Switch
 Operator Type: Illuminated
 Operator Action: sp ret L to C
 Button Type: Standard Handle
 Bezel Type: Metal
 Color: Red
 Head Type: Round