


Note:

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

ZB4BV4

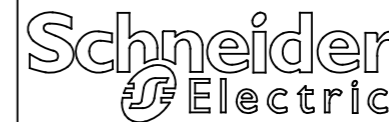

Schneider Electric United States
 North American Division
 Boston One Campus
 800 Federal Street
 Andover, MA 01810, USA
 Phone: +1 8773425173
 Email: CCC@us.schneider-electric.com

Technical Information:

Tightening Torque: 0.8 Nm
 Light Module Electrical Consumption: 24V = 18mA; 120/240V = 14mA
 CE: Yes
 RoHS: Yes
 Contact Configuration: n/a
 Light Module Supply Voltage: 230/240VAC at 50/60Hz

Specification:

Description: Base & Light Module
 Light Module Type: Transformer, BA9 bulb
 Light Module Voltage: 230Vac
 Ampere Rating: N/A
 Contact Material: n/a
 Terminal Type: Screw Clamp
 Utilization Category: n/a
 Used On: ZB4 Metal Operators