


**Note:**

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

**ZB4BW063**

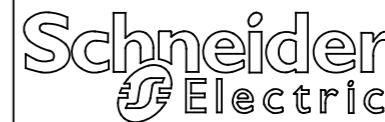

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Tightening Torque: 0.8 Nm  
 Light Module Electrical Consumption: 24V = 18mA; 120/240V = 14mA  
 CE: Yes  
 RoHS: Yes  
 Contact Configuration: 2 N.O.  
 Light Module Supply Voltage: n/a

**Specification:**

Description: Base, Contact, & Light Module  
 Light Module Type: Full Voltage, BA9 bulb  
 Light Module Voltage: <250V direct supply  
 Ampere Rating: 10A  
 Contact Material: Silver Alloy  
 Terminal Type: Screw Clamp  
 Utilization Category: AC-15; DC-13  
 Used On: ZB4 Metal Operators