


EcoStruxure Modular Data Center All-In-One Containers

Quick Reference Sheet (480/208V, 60Hz)

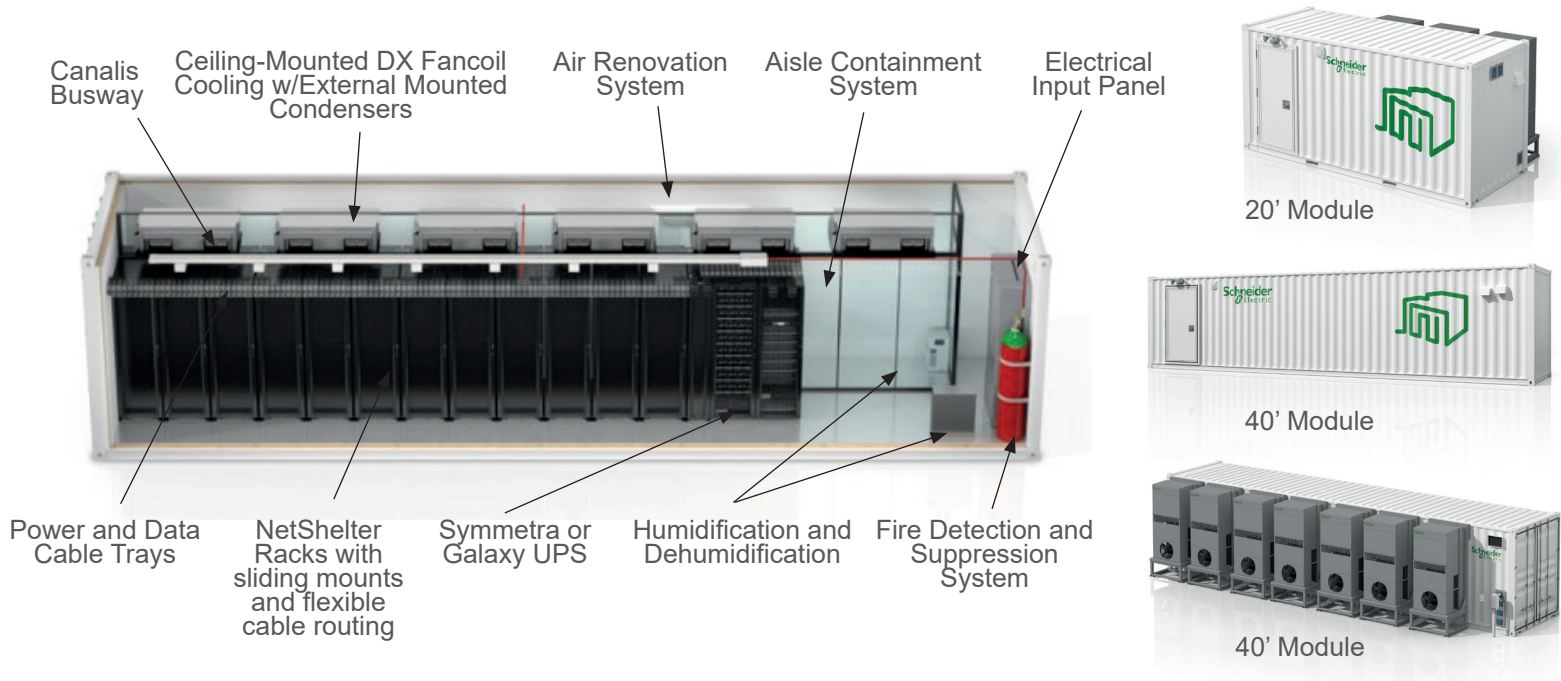

	20' All-In-One 25kW, 5 Racks PFMICC025W1N05D	40' All-In-One 75kW, 12 Racks PFMICC075W1N12C (480V) PFMICC075W1N12D (208V)
Power		
Input/Output Voltage	208V AC, 3 Phase, 60 Hz	208V AC/480V AC, 3 Phase, 60 Hz
ATS / Amp	I-Line / 250A	I-Line / 800A
Total IT Load	25kW (5 racks at 5kW per rack)	75kW (12 racks at 6.25kW per rack)
Rack Distribution	AP8865 Rack PDU, 8.6kW, 208V, (1 per rack)	AP8865 Rack PDU, 8.6kW, 208V, (1 per rack)
UPS / UPS Redundancy	Symmetra PX 40kW / N+1	Symmetra PX, 90kW / N+1
Battery Type	VRLA – Long Life Battery Modules	VRLA – Long Life Battery Modules
Cooling		
Type	W72AAP/W72LAP Wallmount Cooling Unit	W72AAP/W72LAP Wallmount Cooling Unit
Racks		
Rack - Qty	AR3100 - x5 (42U x 600mm (w) x 1070mm (d))	AR3100 - x11 (42U x 600mm (w) x 1070mm (d)) AR3150 -x1 (42U x 750mm (w) x 1070mm (d))
Hot Aisle / Cold Aisle	22in - 36in (racks on adjustable slides to access hot/cold aisle)	22in - 36in (racks on adjustable slides to access hot/cold aisle)
Safety		
Fire Suppression and Detection	Novec 1230, Agent Releasing Control panel with smoke/heat detection, and audible strobe/alarms	Novec 1230, Agent Releasing Control panel with smoke/heat detection, and audible strobe/alarms
Exits	1 Primary	1 Primary
Monitoring	Netbotz 750 with EcoStruxure IT Expert Software	Netbotz 750 with EcoStruxure IT Expert Software
Physical		
L/H/W	20ft / 9.5ft / 8ft	40ft / 9.5ft / 8ft