


Product data sheet

Characteristics

VDIP185X46020

Actassi CL-MNC6A Patchcord S/FTP 4P Cat6A
550MHz LSZH 2m Grey

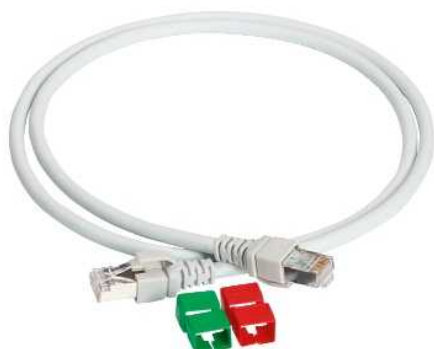

Main

Range	Actassi
Product	Patch cord
Product compatibility	Coloured clips blue Coloured clips yellow Coloured clips green Coloured clips red
Performance	6 _A
Colour	Grey patchcord

Complementary

Provided equipment	Coloured clips red Coloured clips green Coloured clips grey
Cable shielding type	S/FTP
Communication network type	10GBASE-T
Transmission frequency	550 MHz
Input impedance	100 Ohm
Connector type	RJ45
Material	PE (polyethylene) wire insulation Solid bare copper conductor
Standards	ISO/IEC 11801:2011 Ed.2.2 EN 50173 Ed.3 EIA/TIA-568-C.2 IEC 61935-2
Product certifications	Delta
Quantity per set	1
Cable length	2 m

Environment

Environmental characteristic	LSZH (low smoke zero halogen) jacket
Temperature range	-20...60 °C
Ambient air temperature for storage	-20...60 °C
Ambient air temperature for installation	0...50 °C
Temperature resistance	60 °C

Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS (date code: YYWW)	Compliant - since 1144 - Schneider Electric declaration of conformity
REACH	Reference contains SVHC above the threshold - go to CaP for more details
Product end of life instructions	Need no specific recycling operations