
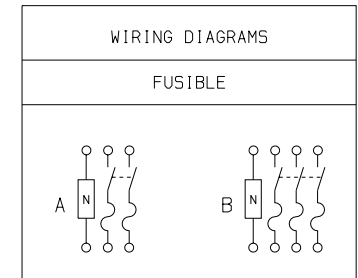


NEMA TYPE 3R
NO KNOCKOUTS

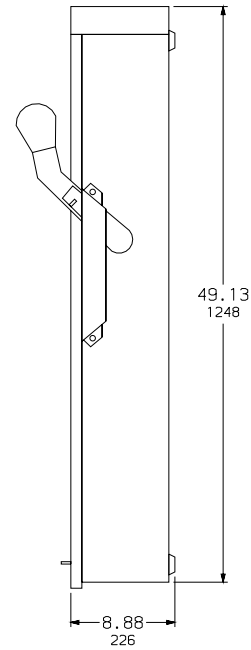

TERMINAL LUGS ‡			
AMPERES	MAX. WIRE	MIN. WIRE	TYPE
600	(2) 500 KCMIL	(2) #4 AWG	AL OR CU

NOTES: FINISH - GRAY BAKED ENAMEL
 UL LISTED - FILE E-2875
 NEUTRAL - INSULATED GROUNDABLE.
 SUITABLE FOR USE AS SERVICE EQUIPMENT
 SHORT CIRCUIT CURRENT RATINGS:
 10,000 AMPERES WHEN USED WITH OR PROTECTED BY CLASS H OR K FUSES.
 100,000 AMPERES WHEN USED WITH OR PROTECTED BY CLASS R FUSES.
 • 100,000 AMPERES WITH 300VAC CLASS T FUSES.
 ‡ LUGS SUITABLE FOR (2) #4 AWG-600 KCMIL (AL/CU). WIRE BENDING SPACE PROVIDED FOR (2) 500 KCMIL MAX. USE 75°C CONDUCTORS.

DUAL DIMENSIONS, INCHES
MILLIMETERS

CATALOG NUMBER	VOLTAGE RATINGS	WIRING DIAG.	HORSEPOWER RATING	
			240VAC	
			STD.	MAX.
D226NR	240VAC	A	-	-
D326NR	240VAC	B	75	150
D326NTR	240VAC	B	75	-

GENERAL DUTY SAFETY SWITCHES
 VISIBLE BLADE TYPE
 600 AMPERE
 ENCLOSURE - NEMA TYPE 3R RAINPROOF

SQUARE D COMPANY

DWG. NO. 1881