


NEMA TYPE 1

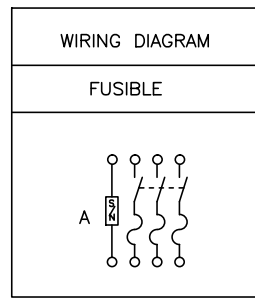

KNOCKOUTS		
SYMBOL	CONDUIT SIZE	
	IN	MM
A	.50	13
B	.75	19
C	1.00	25
D	1.25	32
E	1.50	38
F	2.00	51
G	2.50	64
H	3.00	76
I	3.50	89
J	4.00	102

TERMINAL LUGS ‡			
AMPERES	MAX WIRE	MIN WIRE	TYPE
800	(3) 500 KCMIL	(3) 3/0 AWG	AL OR CU

DUAL DIMENSIONS: INCHES
MILLIMETERS

CATALOG NUMBER	VOLTAGE RATINGS	WIRING DIAG	HORSEPOWER RATINGS	
			240VAC	STD
			3Ø	
T327N	240VAC	A	100	

NOTES:
 FINISH - GRAY BAKED ENAMEL.
 UL LISTED - FILE E-2875
 NEUTRAL - INSULATED GROUNDABLE
 SUITABLE FOR USE AS SERVICE EQUIPMENT
 SHORT CIRCUIT CURRENT RATINGS:
 100,000 AMPERES WITH CLASS T FUSES.
 USE 300VAC CLASS T FUSES ONLY.
 ‡ LUGS SUITABLE FOR 75°C AL/CU CONDUCTORS.

GENERAL DUTY SAFETY SWITCHES
 VISIBLE BLADE TYPE
 800 AMPERE
 ENCLOSURE - NEMA TYPE 1 GENERAL PURPOSE

SQUARE D
 by **Schneider Electric**

DWG# 1882
 NO. 1882