
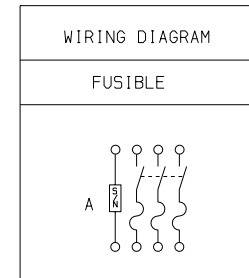


.44 DIA  
11  
(4 HOLES)

NEMA TYPE 3R  
NO KNOCKOUTS

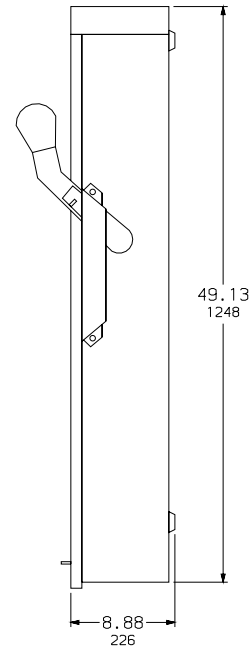

TERMINAL LUGS ‡			
AMPERES	MAX. WIRE	MIN. WIRE	TYPE
800	(3) 500 KCMIL	(3) 3/0 AWG	AL OR CU

NOTES: FINISH - GRAY BAKED ENAMEL.  
UL LISTED - FILE E-2875  
NEUTRAL - INSULATED GROUNDABLE.  
SUITABLE FOR USE AS SERVICE EQUIPMENT  
SHORT CIRCUIT CURRENT RATINGS:  
100,000 AMPERES WITH CLASS T FUSES.  
USE 300VAC CLASS T FUSES ONLY.  
‡ LUGS SUITABLE FOR 75°C AL/CU CONDUCTORS.

DUAL DIMENSIONS: INCHES  
MILLIMETERS

CATALOG NUMBER	VOLTAGE RATINGS	WIRING DIAG.	HORSEPOWER RATINGS	
			240VAC	STD.
T327NR	240VAC	A	3Ø	100

GENERAL DUTY SAFETY SWITCHES  
VISIBLE BLADE TYPE  
800 AMPERE  
ENCLOSURE - NEMA TYPE 3R RAINPROOF

**SQUARE D COMPANY**

DWG. NO. 1884